

# E11720




## Splitter box

ZDO6H050MSS0005H07

Article no longer available - archive entry

Alternative articles: EBC017

When selecting an alternative article and accessories please note that technical data may differ!

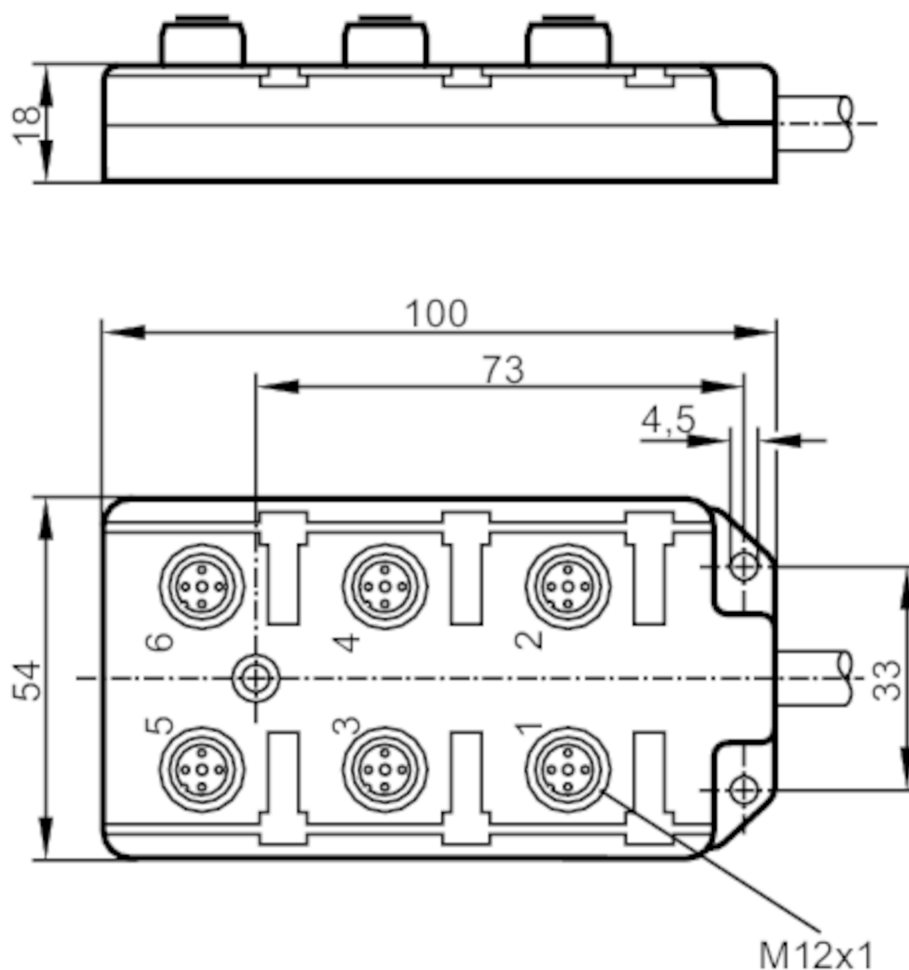

### Application

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes                                                    |

### Electrical data

|                                   |     |                   |
|-----------------------------------|-----|-------------------|
| Operating voltage                 | [V] | < 60 AC / < 75 DC |
| Protection class                  |     | II                |
| Max. current load per module/slot | [A] | 4                 |
| Max. current load total           | [A] | 12                |

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -15...80 |
| Protection          |      | IP 67    |

# E11720



## Splitter box


ZDO6H050MSS0005H07

| Mechanical data              |     |
|------------------------------|-----|
| Materials                    | TPU |
| Moulded-body material        | TPU |
| Number of ports splitter box | 6   |
| Connector type               | M12 |

| Remarks       |        |
|---------------|--------|
| Pack quantity | 1 pcs. |

| Electrical connection                                                                                                               |  |
|-------------------------------------------------------------------------------------------------------------------------------------|--|
| Cable: 5 m, PUR, Halogen-free, black, Ø 9 mm; 6 x 0.34 mm <sup>2</sup> (43 x Ø 0.1 mm ) + 3 x 0.75 mm <sup>2</sup> (95 x Ø 0.1 mm ) |  |

| Electrical connection - slot                                                                       |  |
|----------------------------------------------------------------------------------------------------|--|
| Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm |  |

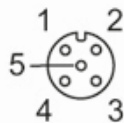

### Connection

|       |           |
|-------|-----------|
| BN    | 1 (1...6) |
| BU    | 3 (1...6) |
| GN/YE | 5 (1...6) |
| WH    | 4 (1)     |
| GN    | 4 (2)     |
| YE    | 4 (3)     |
| GY    | 4 (4)     |
| PK    | 4 (5)     |
| RD    | 4 (6)     |

|                |        |
|----------------|--------|
| Core colours : |        |
| BN =           | brown  |
| BU =           | blue   |
| GN =           | green  |
| GY =           | grey   |
| PK =           | pink   |
| RD =           | red    |
| WH =           | white  |
| YE =           | yellow |