

E11725




Splitter box

ZDO8H050MSS0000-00STAK120MSS

Article no longer available - archive entry

Alternative articles: EBC009
When selecting an alternative article and accessories please note that technical data may differ!

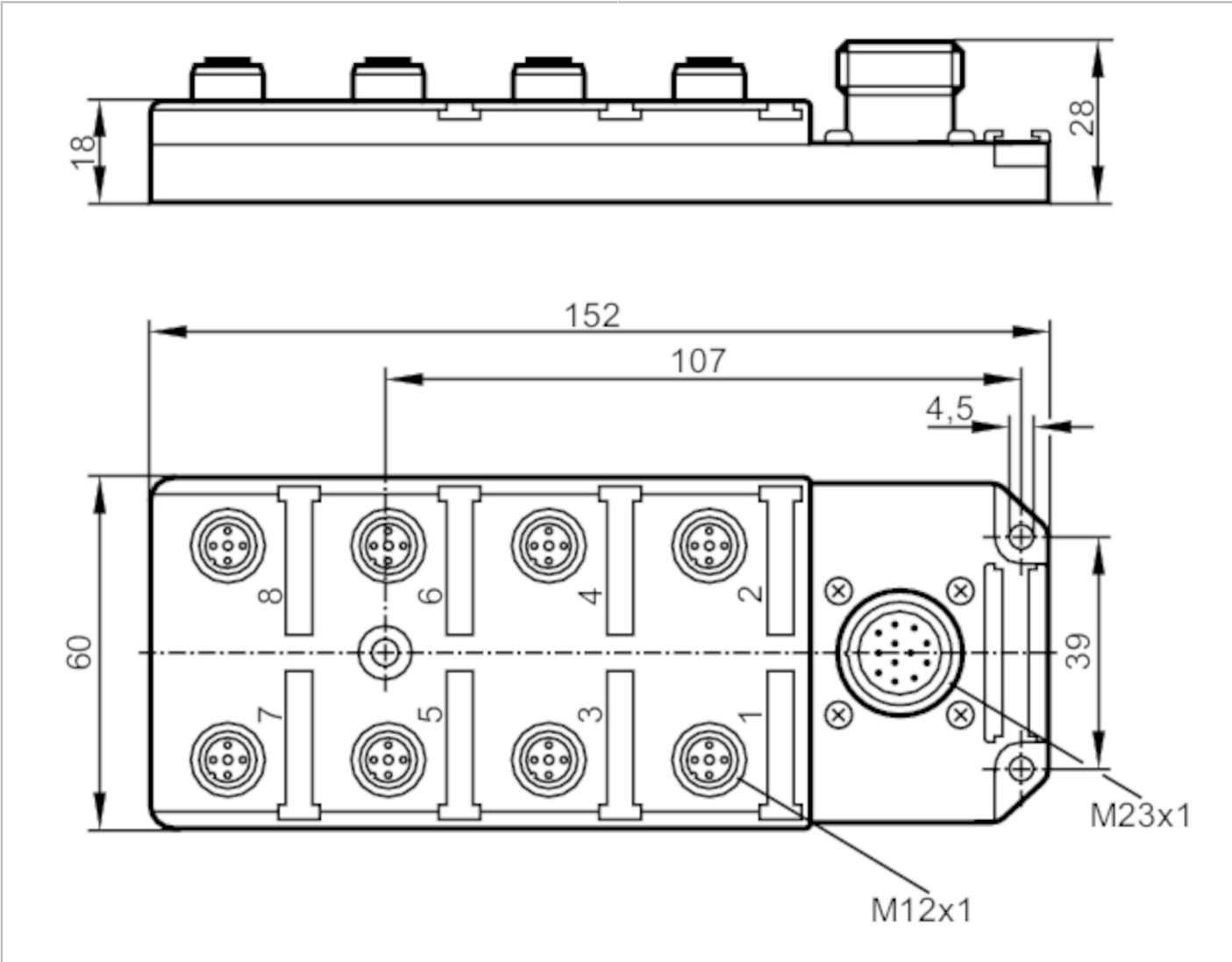

Application

Special feature

Free from silicone; Gold-plated contacts

Free from silicone

yes

Electrical data

Operating voltage

[V]

< 60 AC / < 75 DC

Protection class

II

Max. current load per
module/slot

[A]

4

Max. current load total

[A]

12

Operating conditions

Ambient temperature

[°C]

-15...80

Protection

IP 67

E11725



Splitter box

ZDO8H050MSS0000-00STAK120MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 152
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		8
Connector type		M12


Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm



Connection

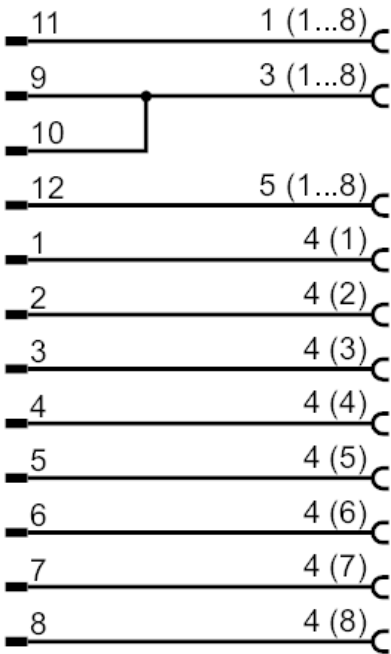

E11725



Splitter box

ZDO8H050MSS0000-00STAK120MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

