


Splitter box

ZDO8H050MSS0010H11

Article no longer available - archive entry

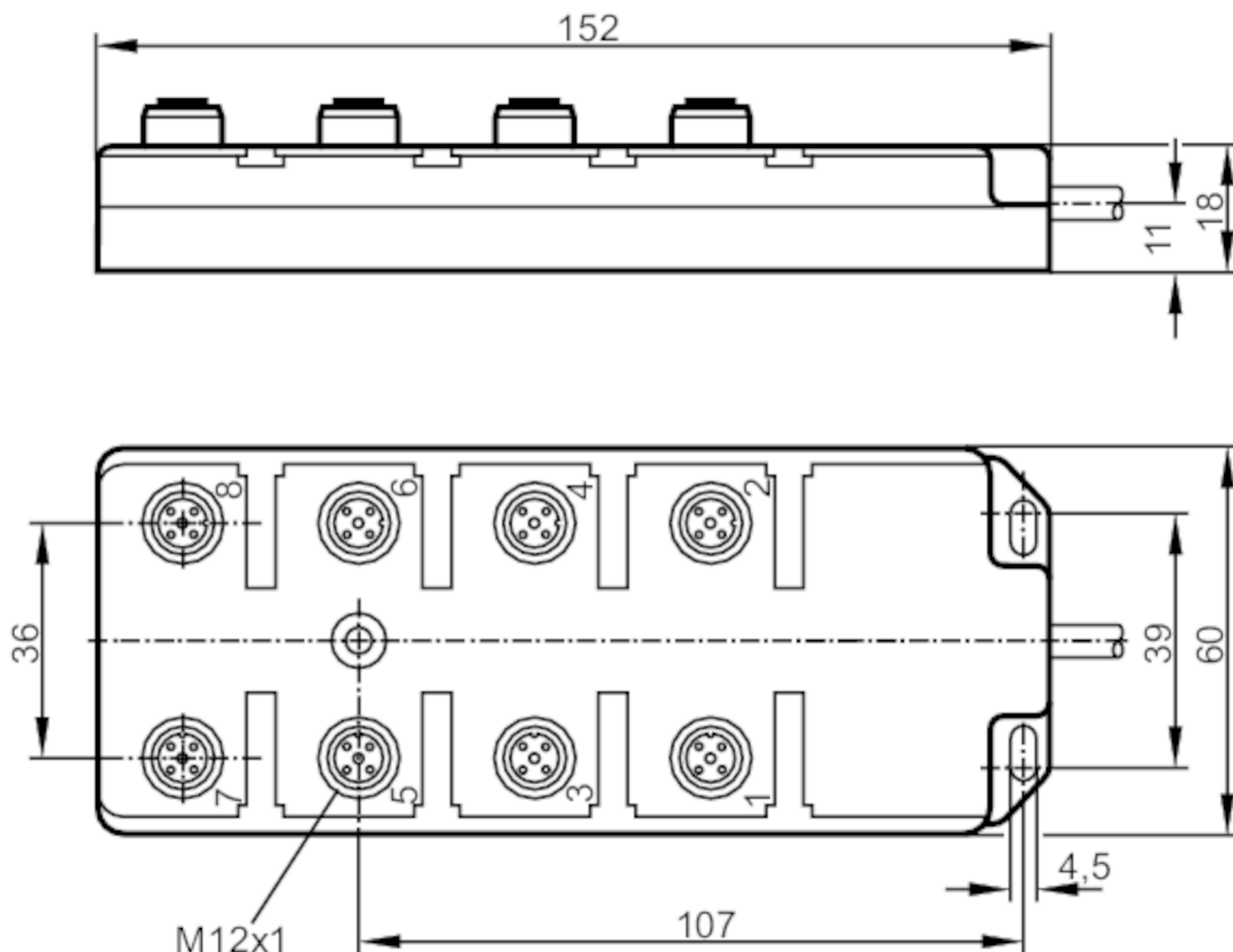

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-15...80
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU

E11733



Splitter box

ZDO8H050MSS0010H11

Number of ports splitter box	8
Connector type	M12

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 11.6 mm; 16 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

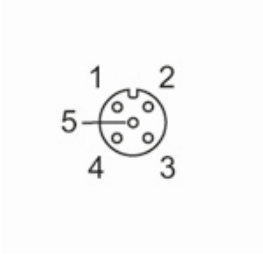

E11733



Splitter box

ZDO8H050MSS0010H11

Connection

<u>BN</u>	1 (1...8)	C
<u>BU</u>	3 (1...8)	C
<u>GN/YE</u>	5 (1...8)	C
<u>GY/PK</u>	2 (1)	C
<u>RD/BU</u>	2 (2)	C
<u>WH/GN</u>	2 (3)	C
<u>BN/GN</u>	2 (4)	C
<u>WH/YE</u>	2 (5)	C
<u>YE/BN</u>	2 (6)	C
<u>WH/GY</u>	2 (7)	C
<u>GY/BN</u>	2 (8)	C
<u>WH</u>	4 (1)	C
<u>GN</u>	4 (2)	C
<u>YE</u>	4 (3)	C
<u>GY</u>	4 (4)	C
<u>PK</u>	4 (5)	C
<u>RD</u>	4 (6)	C
<u>BK</u>	4 (7)	C
<u>VT</u>	4 (8)	C

	Core colours :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow