


E11738



Connecting cable with socket

ADOGK120MSS0015H12

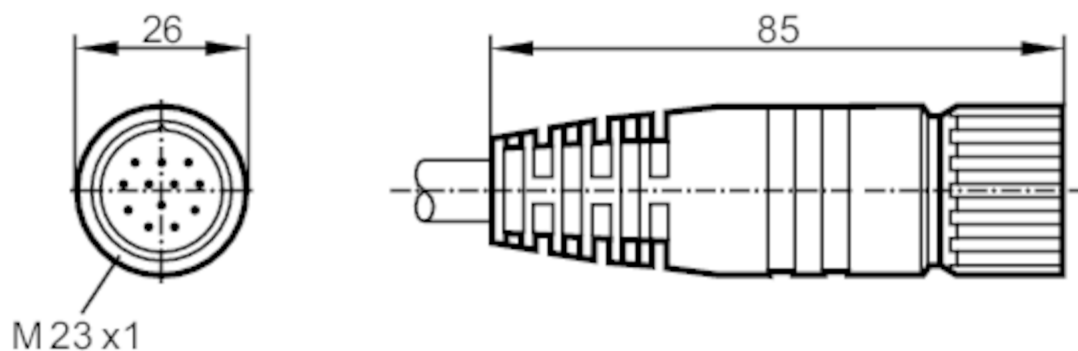

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	< 63 AC/DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 67

Mechanical data

Weight	[g]	2027
Dimensions	[mm]	26 x 26 x 85
Materials		PUR black
Moulded-body material		PUR
Material nut		brass, nickel-plated
Tightening torque	[Nm]	2

Remarks

Pack quantity	1 pcs.
---------------	--------

E11738



Connecting cable with socket


ADOGK120MSS0015H12

Electrical connection


Cable: 15 m, PUR, Halogen-free, black, Ø 9.3 mm; 8 x 0.5 mm² (63 x Ø 0.1 mm) + 3 x 1.0 mm² (127 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M23, straight; Moulded body: PUR; Locking: brass, nickel-plated

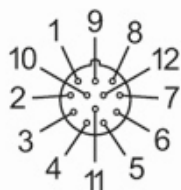

Connection

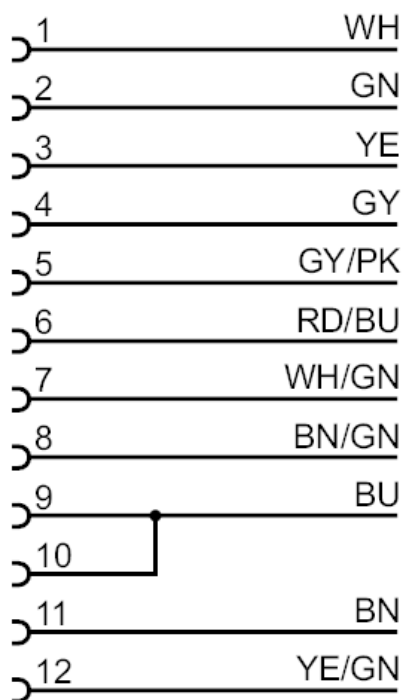

Core colours :
BN = brown
BU = blue
GN = green
GY = grey
PK = pink
RD = red
WH = white
YE = yellow