


Y connection cable

YDOAH040MSS0001H04STGH050MSS

Article no longer available - archive entry

Alternative articles: EVC434

When selecting an alternative article and accessories please note that technical data may differ!

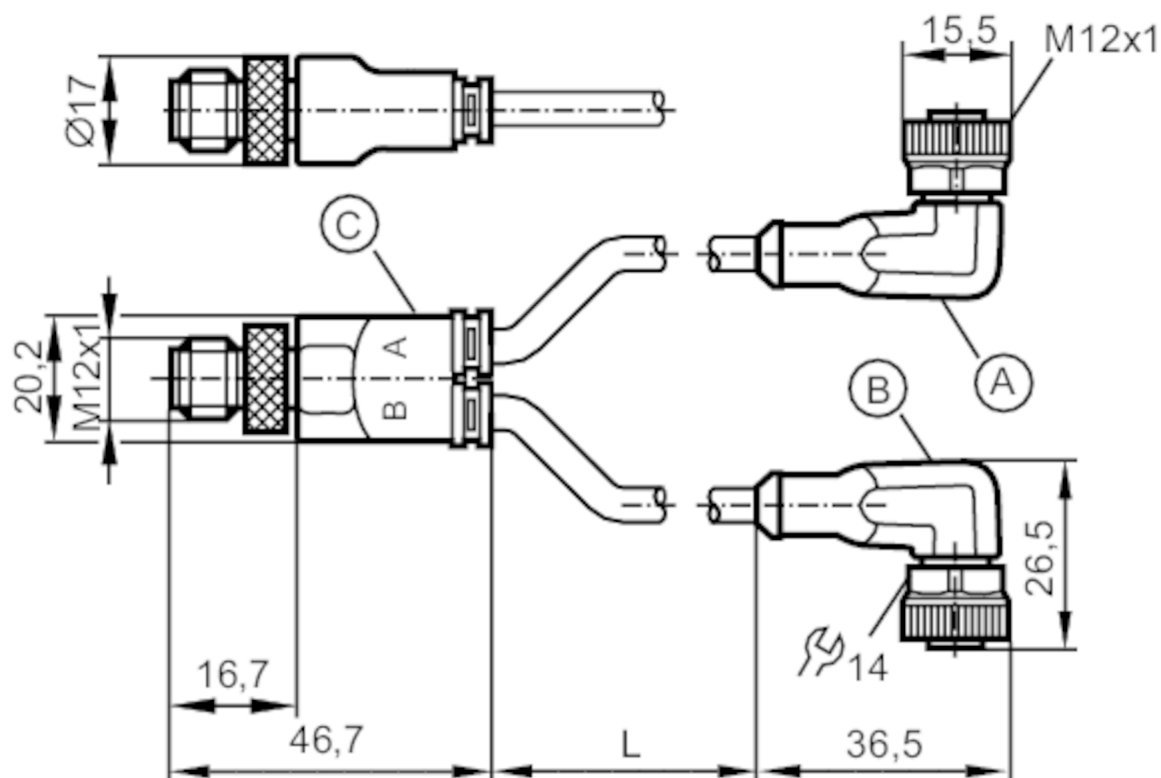

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

Mechanical data

Weight	[g]	0.111
Moulded-body material		TPU
Material nut		brass, nickel-plated
Sealing material		FKM
Number of ports splitter box		2

Remarks

Pack quantity		1 pcs.
---------------	--	--------

Y connection cable


YDOAH040MSS0001H04STGH050MSS

Electrical connection


Cable: 1 m, PUR, Halogen-free, black, Ø 4.9 mm; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, black; Locking: brass, nickel-plated; Contacts: gold-plated

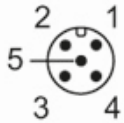

Connection

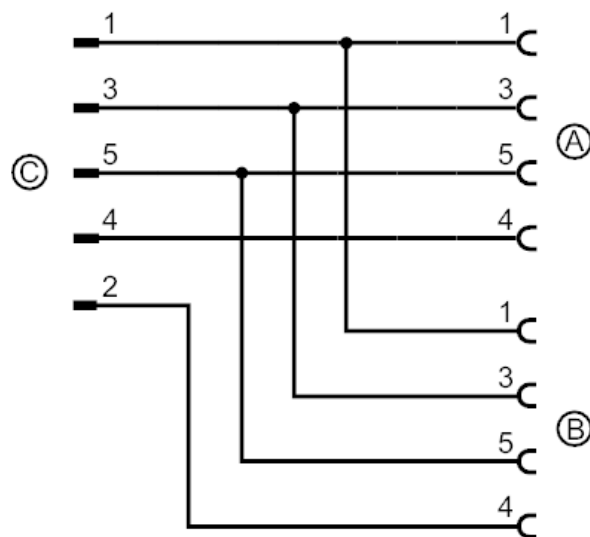

Electrical connection - socket

Connector: 2 x M12, angled; coding: A; Moulded body: TPU, black transparent; Locking: brass, nickel-plated; Sealing: FKM; Contacts: gold-plated

