


E11863



Wirable socket

SDOAH042VASFKPG

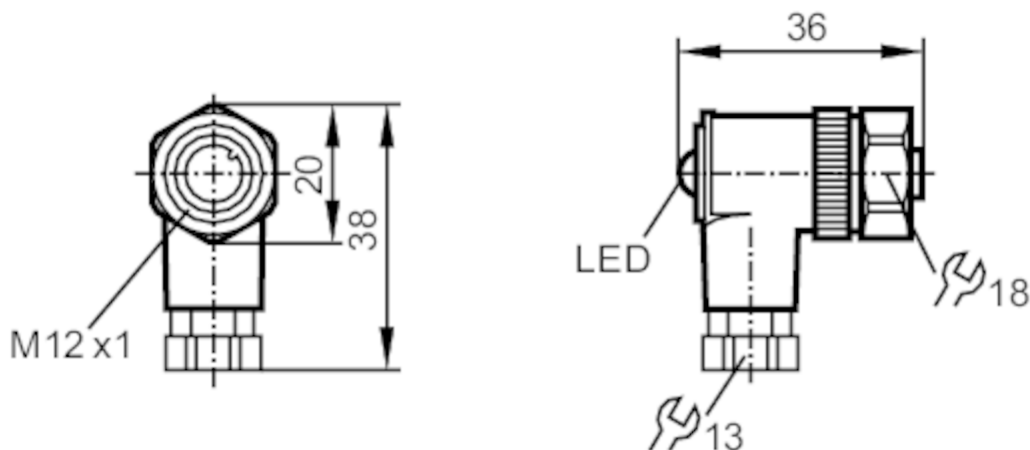

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Max. current load total	[A]	4; (...40 °C)

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67; IP 69K

Mechanical data

Weight	[g]	26.4
Dimensions	[mm]	38 x 20 x 36
Materials		PBT; PA transparent
Moulded-body material		PBT / PA, transparent
Material nut		stainless steel

Displays / operating elements

Display	switching status	1 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------

E11863



Wirable socket

SDOAH042VASFKPG

Electrical connection

screw terminals: ...0.75 mm²; Cable sheath: Ø 4...6 mm

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PBT / PA, transparent; Locking: stainless steel; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Connection

