


Connecting cable with socket

ADOAK120MSS0014B12

Article no longer available - archive entry

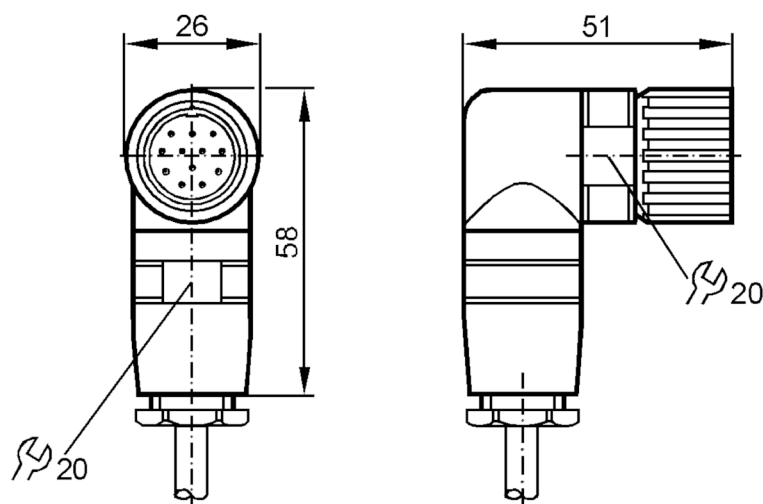

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 65

Mechanical data

Dimensions	[mm]	51 x 26 x 58
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Material nut		brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 14 m, PUR, black, Ø 11 mm; 12 x 1.0 mm²

Electrical connection - plug

Connector: 1 x M23, angled; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated

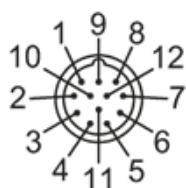

E11016



Connecting cable with socket

ADOAK120MSS0014B12

Connection
