


E11020



Splitter box

ZDO6H05DMSS0010H15

Article no longer available - archive entry

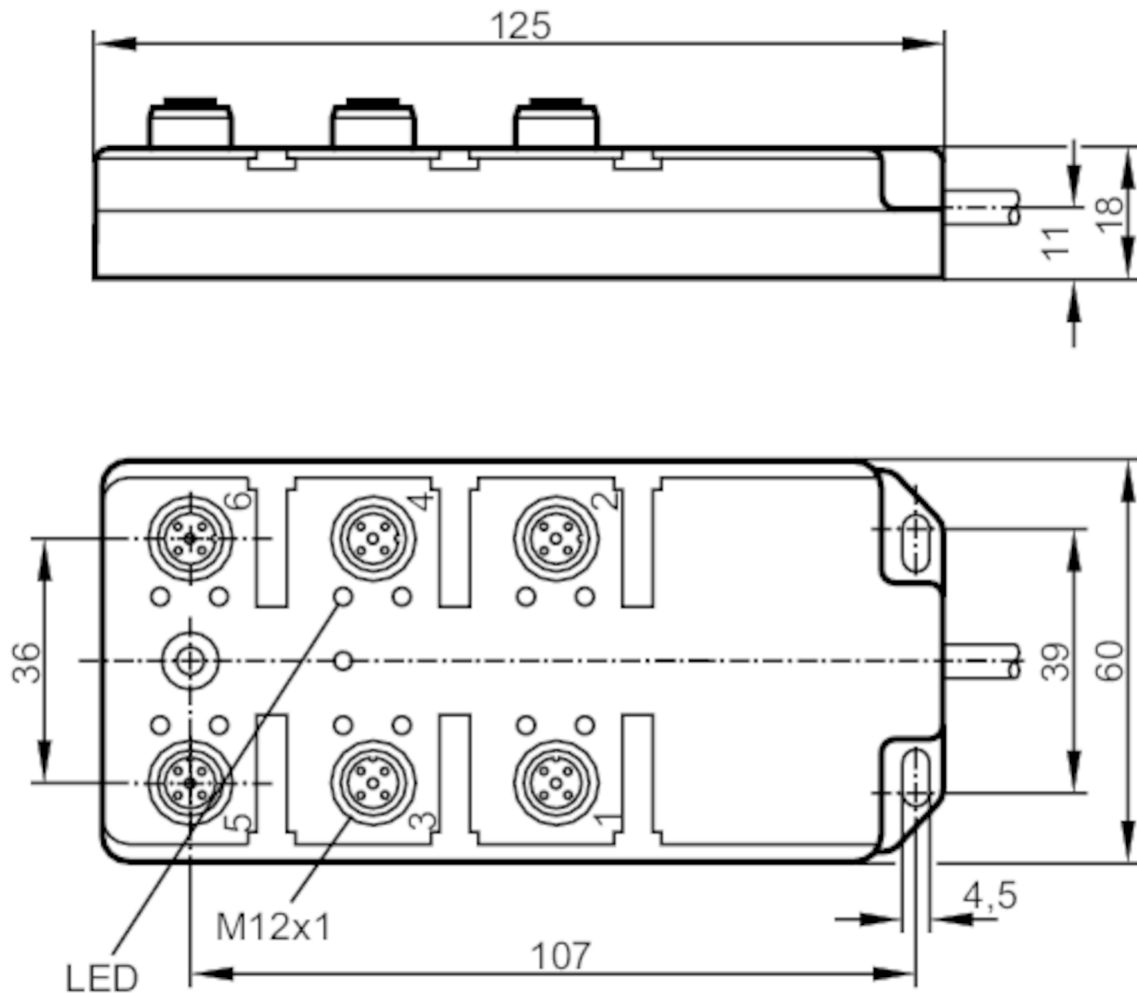

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	12

Outputs

Electrical design	PNP
-------------------	-----

Operating conditions


Ambient temperature	[°C]	-15...80
Protection		IP 67

E11020



Splitter box

 ZDO6H05DMSS0010H15

Mechanical data		
Materials	TPU	
Moulded-body material	TPU	
Number of ports splitter box	6	
Connector type	M12	
Displays / operating elements		
Display	switching status	12 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity	1 pcs.	
Electrical connection		
Cable: 10 m, PUR, Halogen-free; 12 x 0.5 mm ² (63 x Ø 0.1 mm) + 3 x 1.0 mm ² (127 x Ø 0.1 mm)		
Electrical connection - slot		
Connector: 6 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm		
		


E11020

Splitter box

ZDO6H05DMSS0010H15



Connection

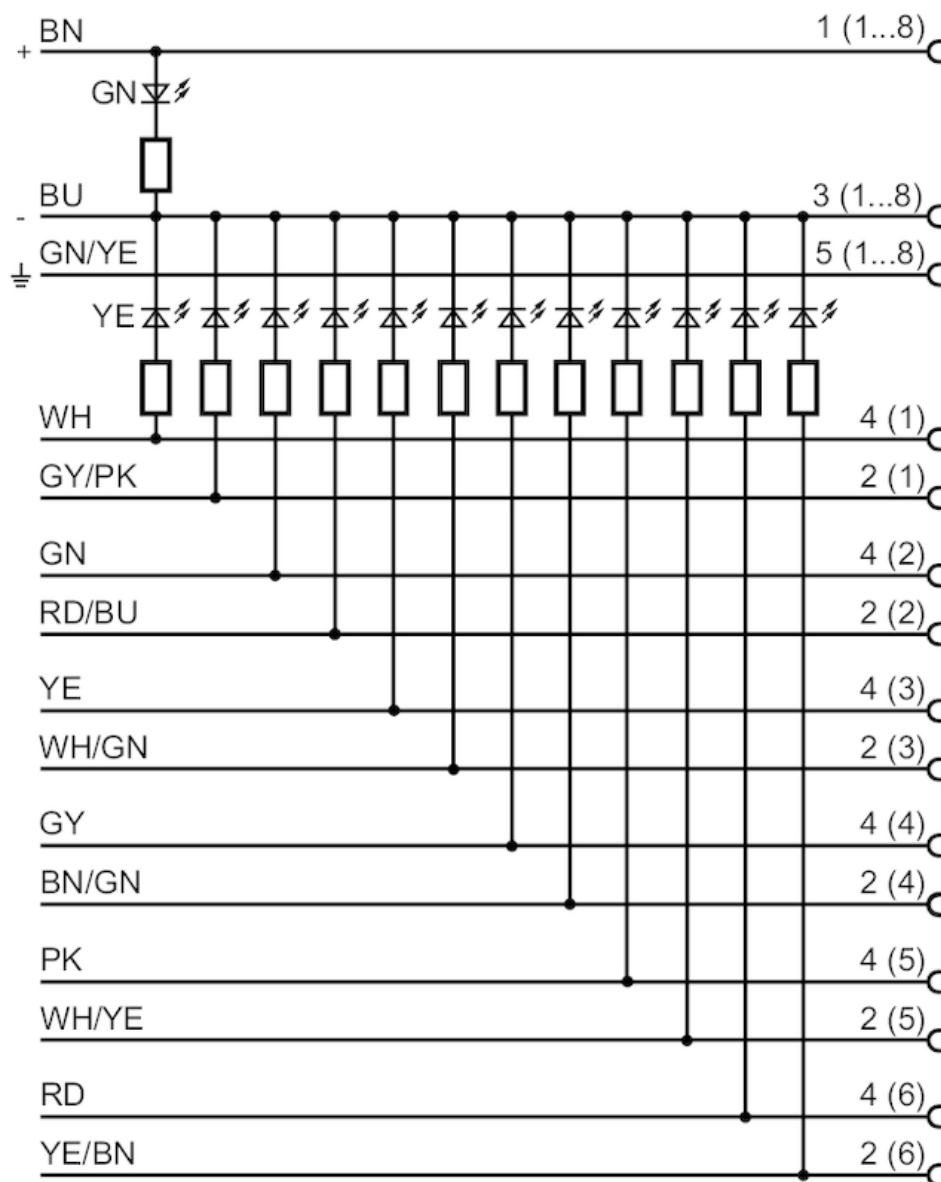

BN =
BU =
GN =
GY =
PK =
RD =
WH =
YE =

Core colours :
brown
blue
green
grey
pink
red
white
yellow