


Connecting cable with socket

ADOAA040VAS0010E04

Article no longer available - archive entry

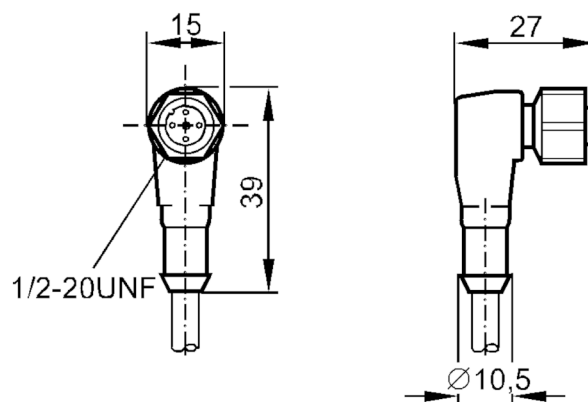

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC
-------------------	-----	----------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Dimensions	[mm]	27 x 15 x 39
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity	1 pcs.
---------------	--------

E11026



Connecting cable with socket


ADOAA040VAS0010E04

Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated

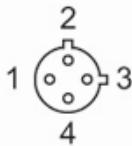

Connection



Core colours :
BK = black
BN = brown
BU = blue
WH = white