




Mounting adapter for capacitive sensors

MOUNTING ADAPTER D34MM POM

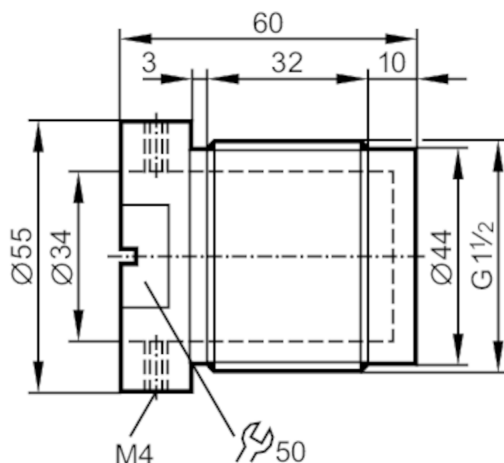

Application

Pressure rating [bar] 8

Operating conditions

Ambient temperature [°C] -25...80

Mechanical data

Weight [g] 83.7

Dimensions [mm] G 1 1/2 / L = 60

Thread designation G 1 1/2

Materials Adapter: POM

Sensor connection clamp adapter Ø 34 mm

Process connection threaded connection G 1 1/2 external thread

Remarks

Pack quantity 1 pcs.