


Mounting adapter for capacitive sensors

MOUNTING ADAPTER M30 POM

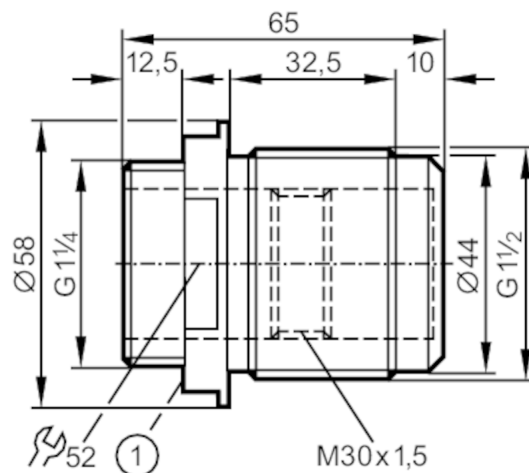

1 O-ring 44 x 2 mm



Application

Medium temperature [°C] -25...100

Medium temperature short time [°C] -25...110

Pressure rating [bar] 8

Mechanical data

Weight [g] 90.5

Dimensions [mm] G 1 1/2 / L = 65

Thread designation G 1 1/2

Materials Adapter: POM; Gasket: EPDM

Sensor connection threaded connection M30 x 1,5 internal thread

Process connection threaded connection G 1 1/2 external thread

Remarks

Pack quantity 1 pcs.