




Jumper cable with valve plug

AVDAA031--S0002A03

Article no longer available - archive entry

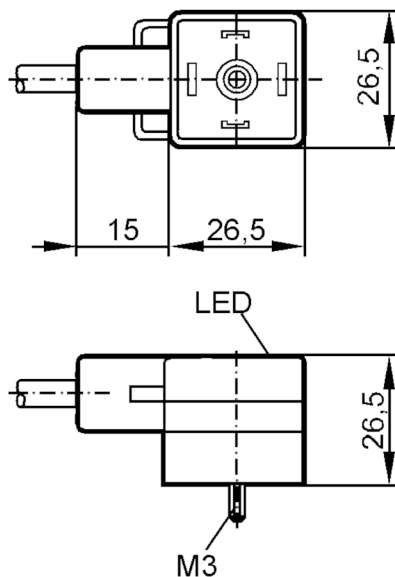

Electrical data

Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	PUR
Moulded-body material	PUR

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Аксессуары

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

E11050



Jumper cable with valve plug


AVDAA031--S0002A03

Electrical connection


Cable: 2 m, PUR / PVC; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: PUR

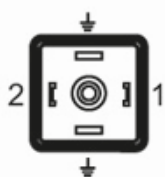

Connection

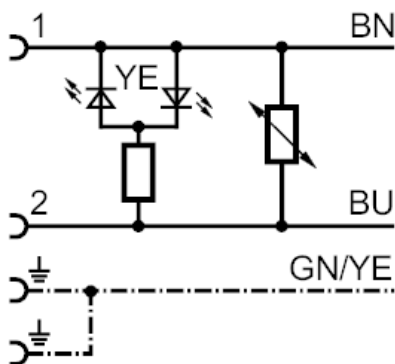

BN =
BU =
GN/YE =

Core colours :
brown
blue
green/yellow