




Jumper cable with valve plug

VSTGH050MSS0003A03VDAA041--S

Article no longer available - archive entry

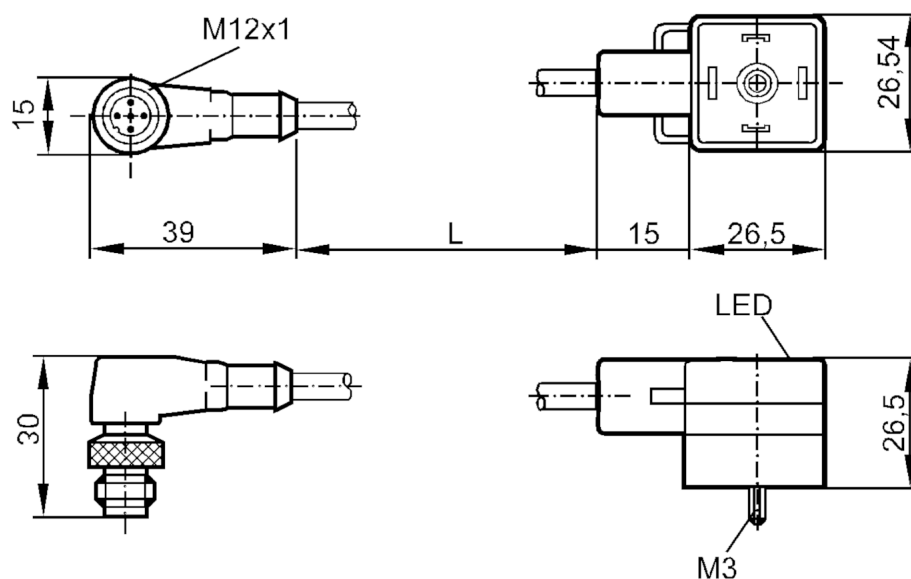

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

< 24 AC/DC

Operating conditions

Ambient temperature

[°C]

-25...90

Protection

IP 67

Mechanical data

Materials

PUR

Moulded-body material

PUR

Material nut

brass, nickel-plated

Аксессуары

Items supplied

screw

panel for labelling

Remarks

Pack quantity

1 pcs.

 


Jumper cable with valve plug

VSTGH050MSS0003A03VDAA041--S

Electrical connection - socket


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Electrical connection

Cable: 3 m, PUR / PVC, Halogen-free; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Connection

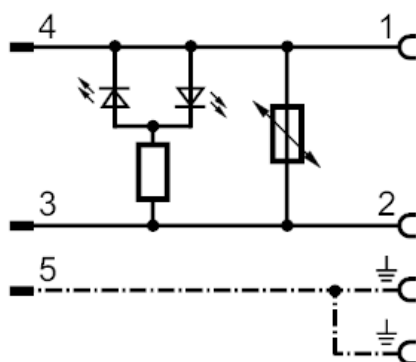

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: PUR; Locking: brass, nickel-plated

