

# E11057




## Wirable plug

SSTA040MSSFKPG

Article no longer available - archive entry

Alternative articles: E11505  
When selecting an alternative article and accessories please note that technical data may differ!

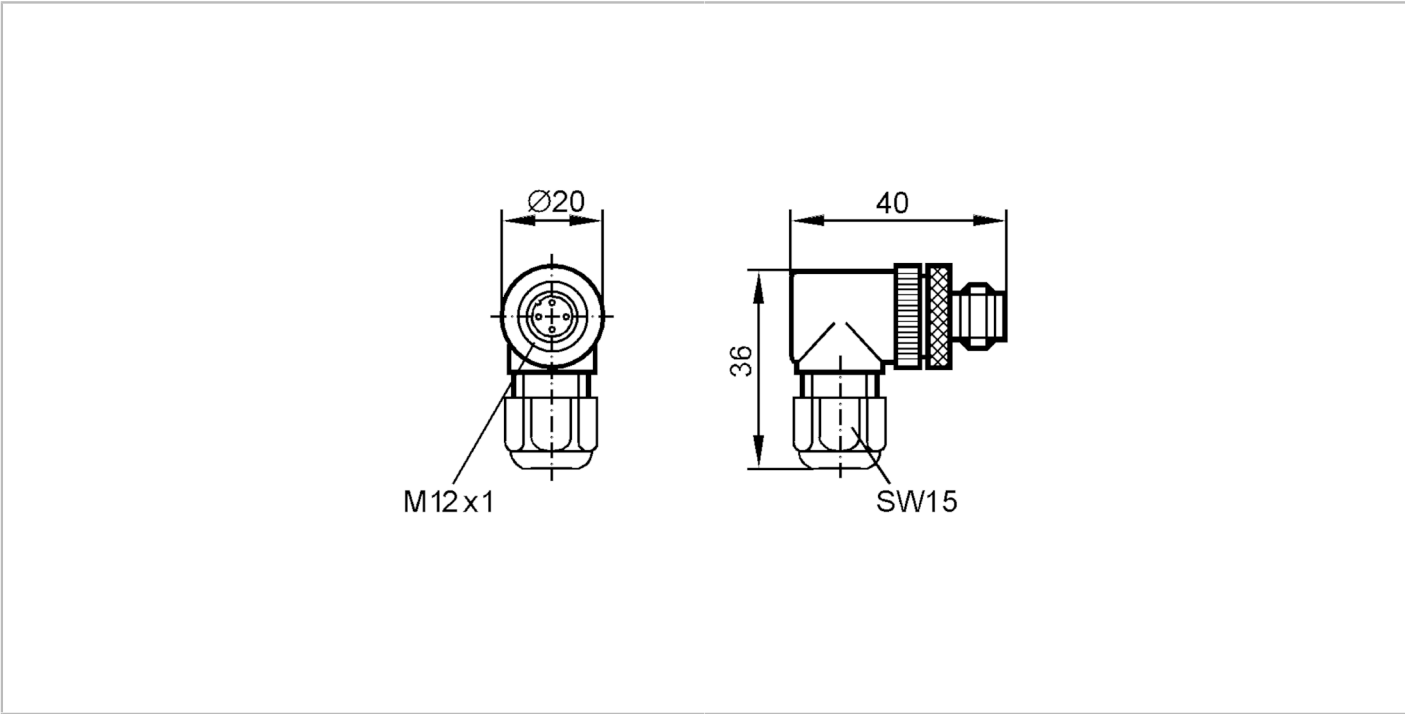

| Electrical data       |      |                      |
|-----------------------|------|----------------------|
| Operating voltage     | [V]  | < 125 AC / < 150 DC  |
| Operating conditions  |      |                      |
| Ambient temperature   | [°C] | -40...85             |
| Protection            |      | IP 67                |
| Mechanical data       |      |                      |
| Dimensions            | [mm] | 20 x 40 x 36         |
| Materials             |      | PA                   |
| Moulded-body material |      | PA                   |
| Material nut          |      | brass, nickel-plated |
| Remarks               |      |                      |
| Pack quantity         |      | 1 pcs.               |

# E11057



## Wirable plug

SSTA040MSSFKPG

### Electrical connection

terminals:

### Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated



### Connection

