

E11058




Wirable socket

SDOAH050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11512
When selecting an alternative article and accessories please note that technical data may differ!

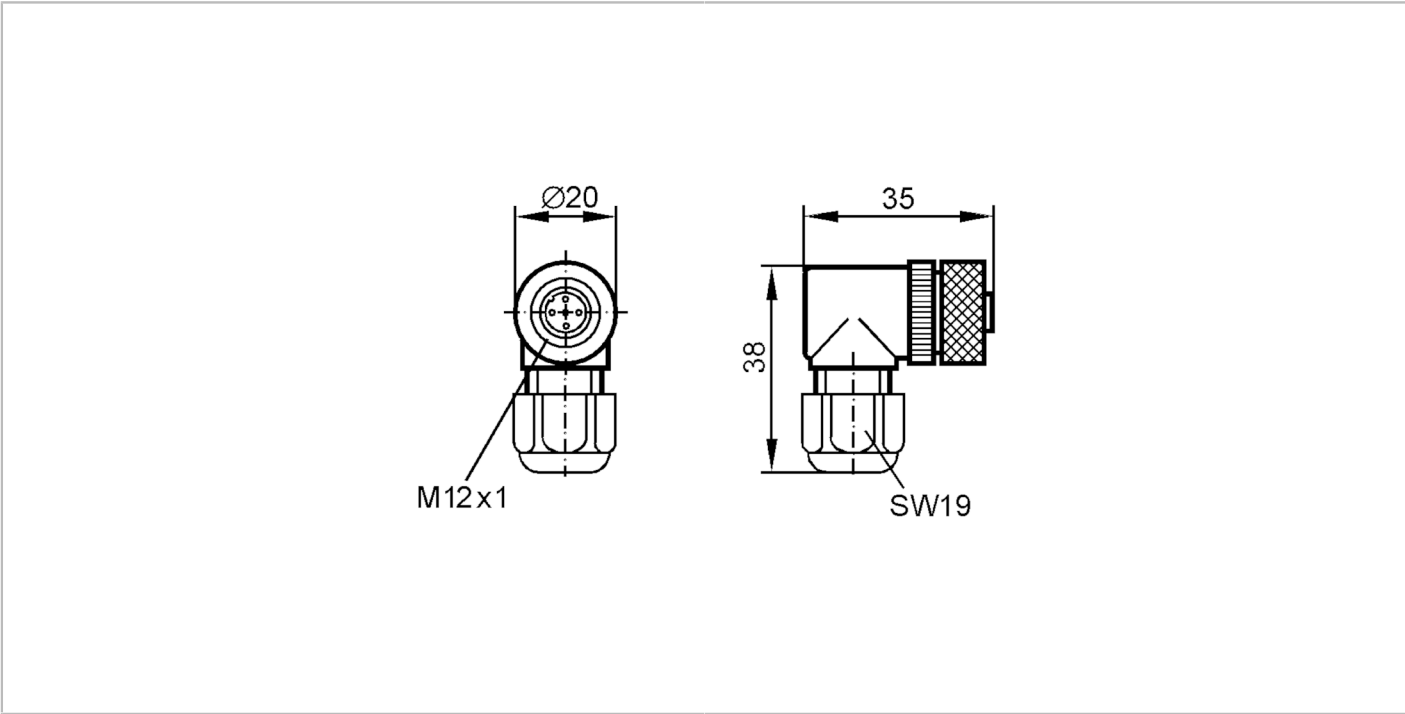

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	38 x 20 x 35
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11058



Wirable socket


SDOAH050MSSFKPG

Electrical connection

terminals:

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated

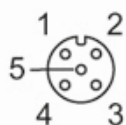

Connection

