


E11060



Connecting cable with socket

ADOAF030MSS0002A03

Article no longer available - archive entry

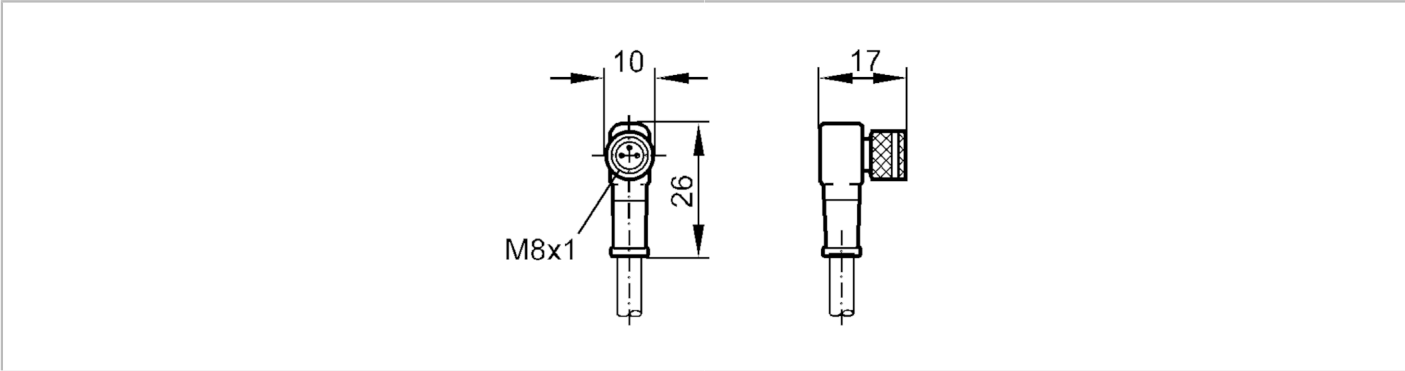

Electrical data

Operating voltage	[M]	< 60 AC / < 75 DC
Protection class		III

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Dimensions	[mm]	17 x 10 x 26
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated

Remarks


Pack quantity		1 pcs.
---------------	--	--------

Electrical connection

Cable: 2 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm²

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

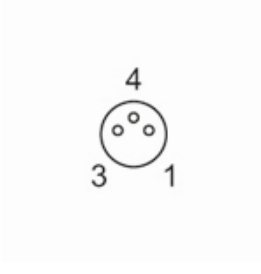

E11060



Connecting cable with socket

ADOAF030MSS0002A03

Connection



BN =	Core colours :	brown
BK =		black
BU =		blue