

E11062




Connection cable

VDOAH043MSS00,3H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC020
When selecting an alternative article and accessories please note that technical data may differ!

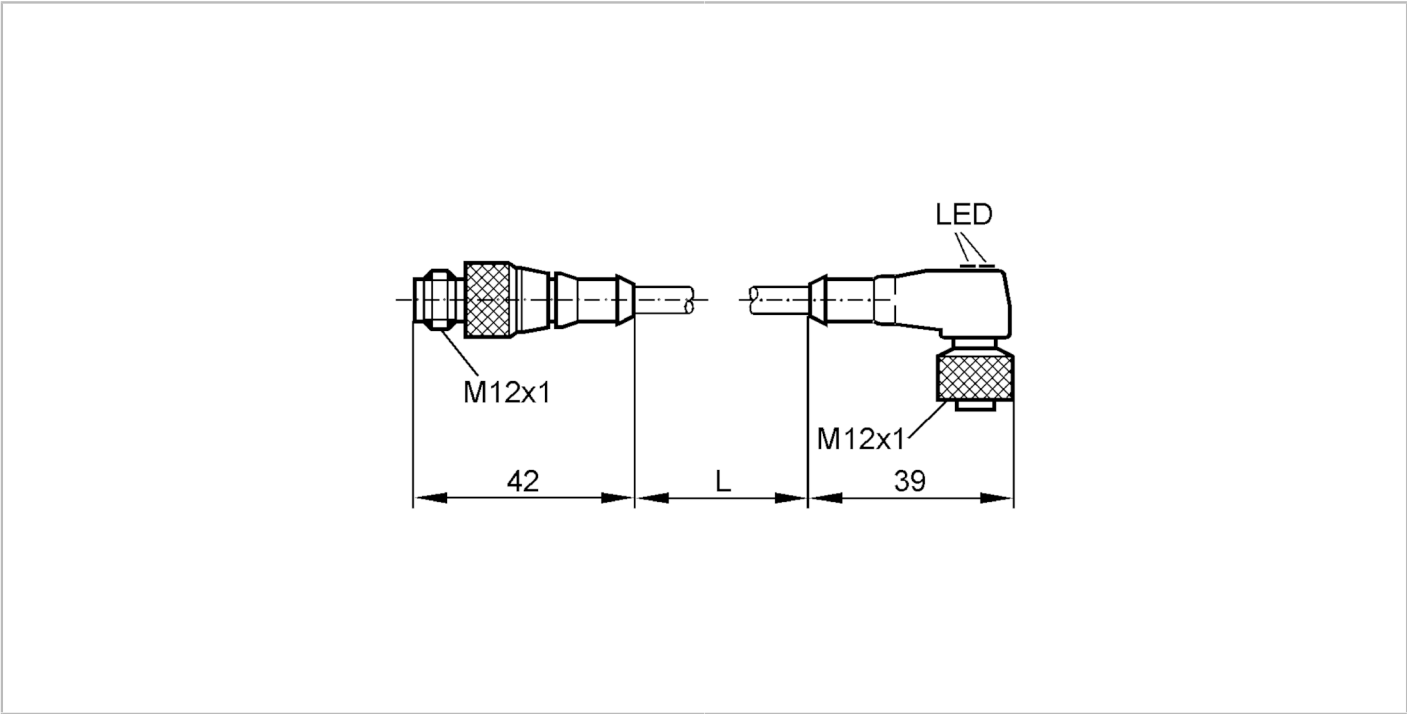

Application		
Special feature	Halogen-free	
Electrical data		
Operating voltage	[V]	10...30 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection	IP 67	
Mechanical data		
Materials	TPU	
Moulded-body material	TPU	
Material nut	brass, nickel-plated	
Displays / operating elements		
Display	switching status	2 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity	1 pcs.	



Connection cable

VDOAH043MSS00,3H04STGH040MSS

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 0.3 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm² (43 x Ø 0.1 mm)

Connection



Core colours :
 BK = black
 BN = brown
 BU = blue
 WH = white

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

