

E11103




Wirable socket

SDOGH050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11511
When selecting an alternative article and accessories please note that technical data may differ!

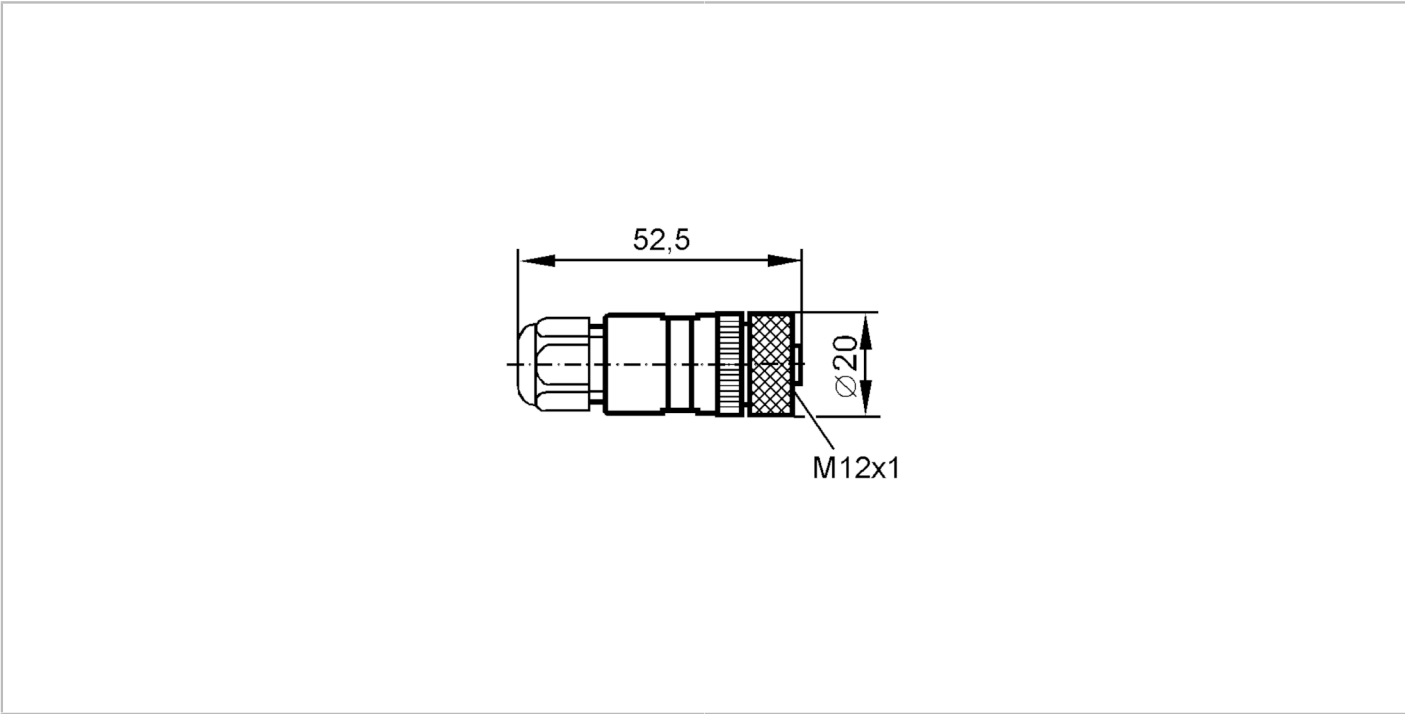

Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Dimensions	[mm]	20 x 20 x 52.5
Materials		PA
Moulded-body material		PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11103



Wirable socket


SDOGH050MSSFKPG

Electrical connection

terminals: ...0.75 mm²; Cable gland: PG 7

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PA; Locking: brass, nickel-plated

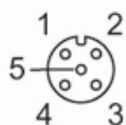

Connection

