

# E11112




## Wirable socket

SDOAH050MSSFKPG

Article no longer available - archive entry

Alternative articles: E11512

When selecting an alternative article and accessories please note that technical data may differ!

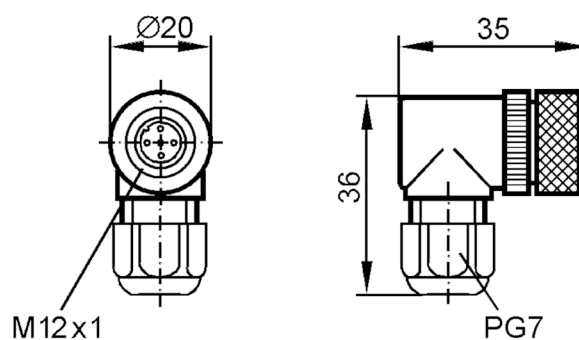

### Electrical data

|                   |     |                   |
|-------------------|-----|-------------------|
| Operating voltage | [V] | < 30 AC / < 36 DC |
|-------------------|-----|-------------------|

### Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
|---------------------|------|----------|

|            |  |       |
|------------|--|-------|
| Protection |  | IP 67 |
|------------|--|-------|

### Mechanical data

|            |      |              |
|------------|------|--------------|
| Dimensions | [mm] | 35 x 20 x 36 |
|------------|------|--------------|

|           |  |    |
|-----------|--|----|
| Materials |  | PA |
|-----------|--|----|

|                       |  |    |
|-----------------------|--|----|
| Moulded-body material |  | PA |
|-----------------------|--|----|

|              |  |                      |
|--------------|--|----------------------|
| Material nut |  | brass, nickel-plated |
|--------------|--|----------------------|

### Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E11112



## Wirable socket


SDOAH050MSSFKPG

### Electrical connection

terminals: ...0.75 mm<sup>2</sup>; Cable gland: PG 7

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PA; Locking: brass, nickel-plated

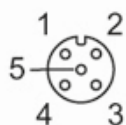

### Connection

