

E11129




Connecting cable with socket

ADOAF030MSS0005X03

Article no longer available - archive entry

Alternative articles: E11239
When selecting an alternative article and accessories please note that technical data may differ!

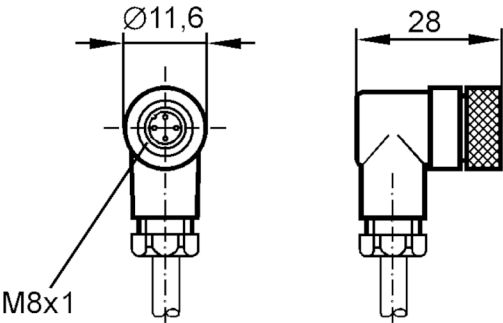

Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-40...85
Protection		IP 67
Mechanical data		
Materials		PBT; PA
Moulded-body material		PBT / PA
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11129



Connecting cable with socket

ADOAF030MSS0005X03

Electrical connection


Cable: 5 m, PTFE; 3 x 0.38 mm²

Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PBT / PA; Locking: brass, nickel-plated



Connection

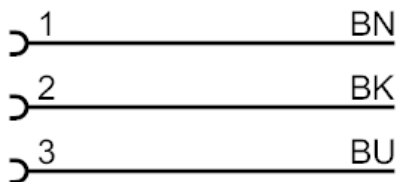

BN =	Core colours :
BK =	brown
BU =	black
	blue