


E11161



Jumper cable with valve plug

VVDAA041--S0003H03STGH030MSS

Article no longer available - archive entry

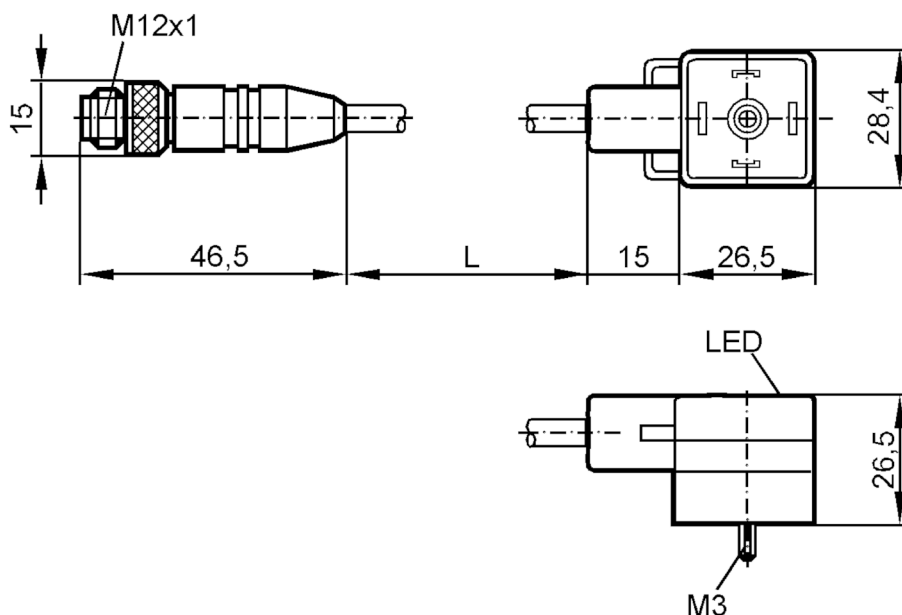

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] < 24 AC/DC

Overvoltage protection yes; (VDR)

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 46.5

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Аксессуары

Items supplied screw

panel for labelling

Remarks

Pack quantity 1 pcs.

E11161




Jumper cable with valve plug

VVDAA041--S0003H03STGH030MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 3 m, PUR, Halogen-free; 3 x 0.5 mm²

Connection

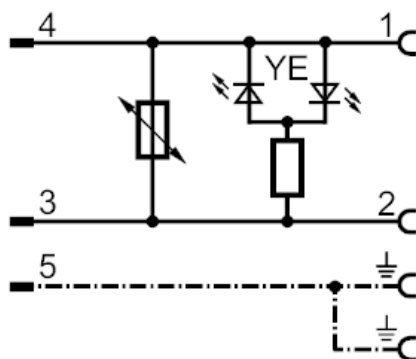

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated

