


# E11168



## Jumper cable with valve plug

VSGH030MSS0001HDOAB031PLS

Article no longer available - archive entry

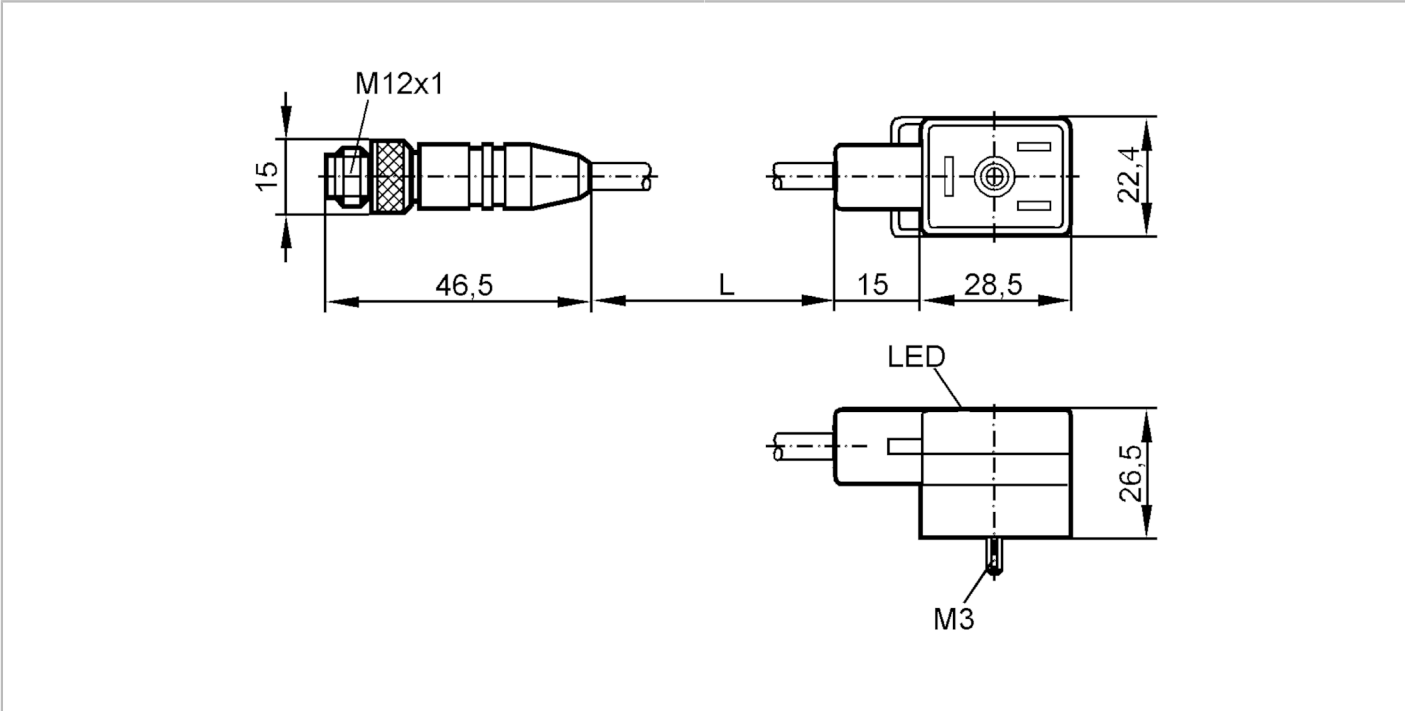

| Application                   |                  |                      |
|-------------------------------|------------------|----------------------|
| Special feature               |                  | Halogen-free         |
| Electrical data               |                  |                      |
| Operating voltage             | [V]              | < 24 AC/DC           |
| Overvoltage protection        |                  | yes; (VDR)           |
| Operating conditions          |                  |                      |
| Ambient temperature           | [°C]             | -25...90             |
| Protection                    |                  | IP 67                |
| Mechanical data               |                  |                      |
| Materials                     |                  | TPU                  |
| Moulded-body material         |                  | TPU                  |
| Material nut                  |                  | brass, nickel-plated |
| Displays / operating elements |                  |                      |
| Display                       | switching status | 1 x LED, yellow      |
| Аксессуары                    |                  |                      |
| Items supplied                |                  | screw                |
|                               |                  | panel for labelling  |
| Remarks                       |                  |                      |
| Pack quantity                 |                  | 1 pcs.               |

# E11168



## Jumper cable with valve plug

VSGH030MSS0001HDOAB031PLS

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



### Electrical connection

Cable: 1 m, PUR, Halogen-free, grey; 3 x 0.5 mm<sup>2</sup>

### Connection

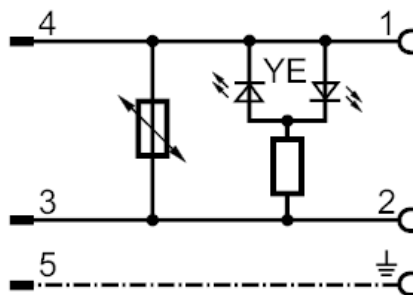

### Electrical connection - socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU; Locking: brass, nickel-plated

