

E11181




Jumper cable with valve plug

VVDAB031--S00,6H03STGH030MSS

Article no longer available - archive entry

Alternative articles: E11432

When selecting an alternative article and accessories please note that technical data may differ!

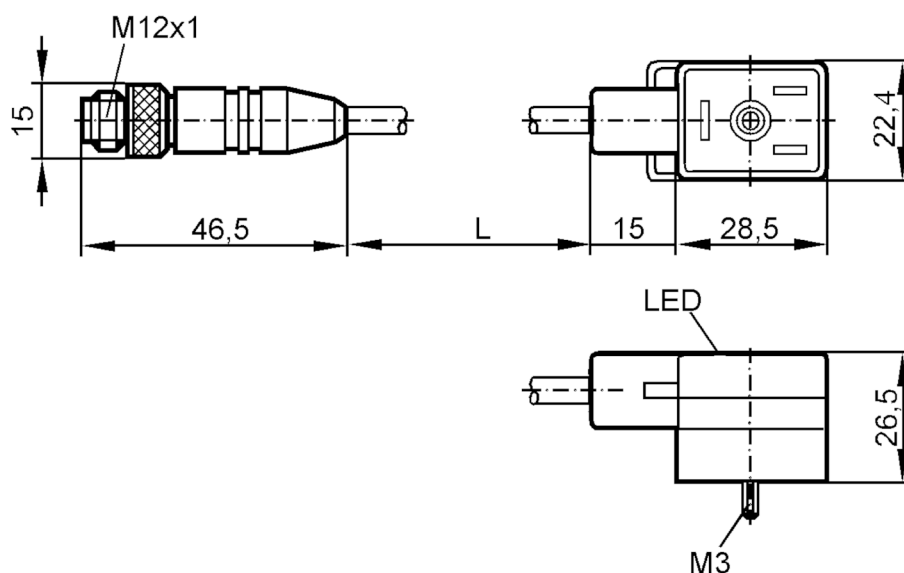

Application		
Special feature		Halogen-free
Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Materials		TPU
Moulded-body material		TPU
Material nut		brass, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
Аксессуары		
Items supplied		screw panel for labelling
Remarks		
Pack quantity		1 pcs.

E11181



Jumper cable with valve plug

VVDAB031--S00,6H03STGH030MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black; 3 x 0.5 mm²

Connection

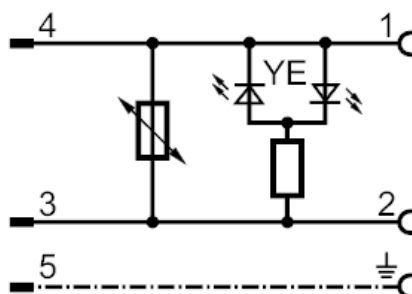

Electrical connection - socket

Connector: 1 x valve type B industrial standard, angled; Moulded body: TPU; Locking: brass, nickel-plated

