


E11187



Jumper cable with valve plug

VVDAA040MSS0001H03STGH020MSS

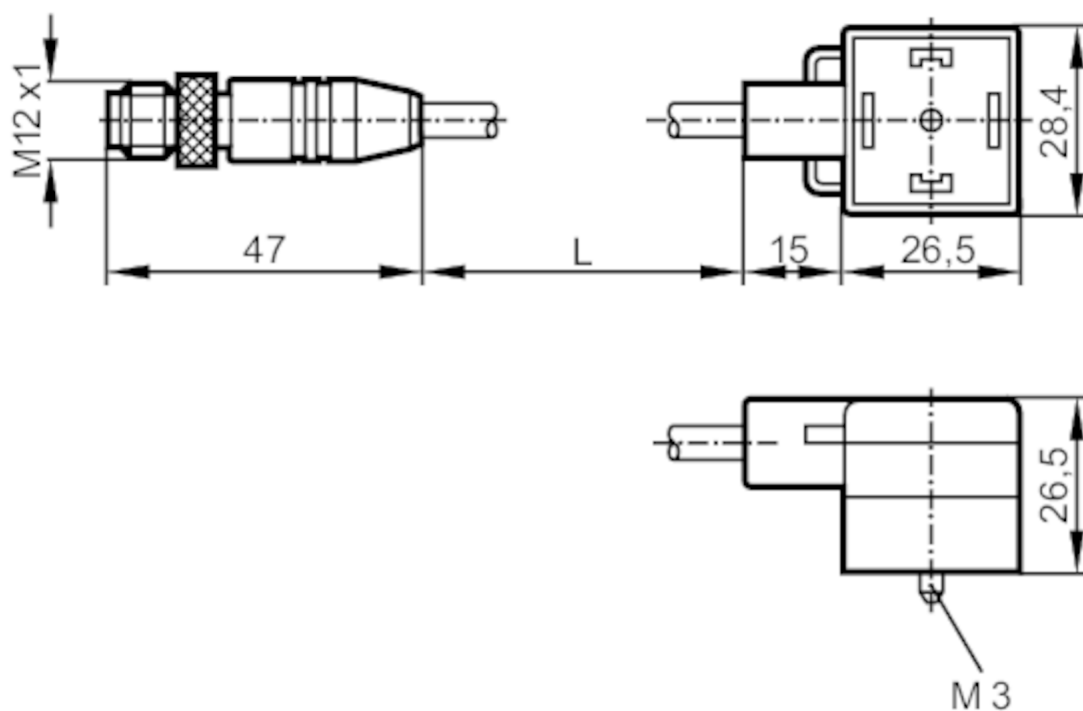

Application	
Application	current measurement
Electrical data	
Operating voltage [V]	< 24 AC/DC
Operating conditions	
Ambient temperature [°C]	-40...90
Protection	IP 67; IP 69K
Mechanical data	
Weight [g]	99.4
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Аксессуары	
Items supplied	screw panel for labelling
Remarks	
Pack quantity	1 pcs.

E11187



Jumper cable with valve plug

VVDAA040MSS0001H03STGH020MSS

Electrical connection - plug

 
Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 1 m, PUR; 2 x 0.75 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

