


E11190



Adapter plug

ESTGF040MSS00,5E04 (M8)

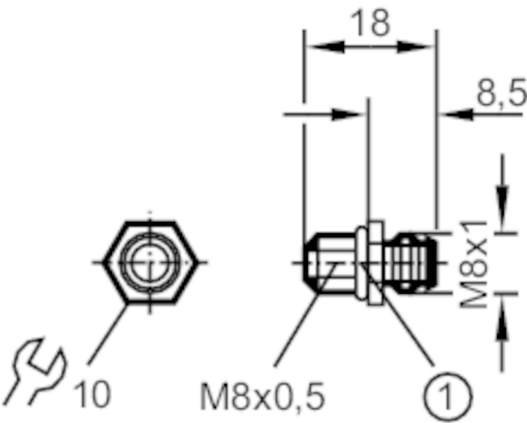

1 O-ring



Electrical data		
Operating voltage	[V]	< 45 AC / < 70 DC
Protection class		III
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	11.6
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11190



Adapter plug

ESTGF040MSS00,5E04 (M8)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.25 mm²

Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: brass, nickel-plated



Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white