

E11195




Adapter socket

EDOGH080MSS00,5E08

Article no longer available - archive entry

Alternative articles: E11601

When selecting an alternative article and accessories please note that technical data may differ!

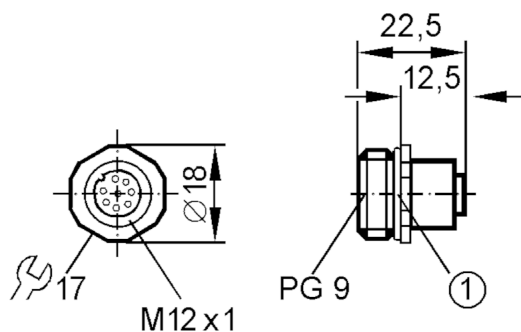

1 O-ring

Electrical data

Operating voltage	[M]	< 30 AC / < 36 DC
-------------------	-----	-------------------

Operating conditions

Ambient temperature	[°C]	-25...90
---------------------	------	----------

Protection	IP 67
------------	-------

Mechanical data

Mounting thread	PG 9
-----------------	------

Materials	brass nickel-plated
-----------	---------------------

Moulded-body material	brass, nickel-plated
-----------------------	----------------------

Remarks

Pack quantity	1 pcs.
---------------	--------

E11195



Adapter socket


EDOGH080MSS00,5E08

Electrical connection

Cable: 0.5 m, PVC; 8 x 0.25 mm² (14 x Ø 0.15 mm)

Electrical connection - socket

Connector: 1 x M12; coding: A; Moulded body: brass, nickel-plated

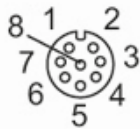

Connection

1	WH
2	BN
3	GN
4	YE
5	GY
6	PK
7	BU
8	RD

	Core colours :
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow