



Connecting cable with socket

ADOGF040MSS0005H04

Article no longer available - archive entry

Alternative articles: EVC151

When selecting an alternative article and accessories please note that technical data may differ!

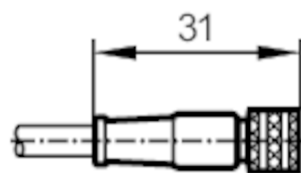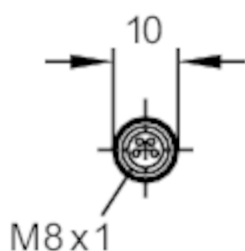

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		III
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...80
Protection		IP 68

Mechanical data

Weight	[g]	139
Dimensions	[mm]	10 x 10 x 31
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E11197



Connecting cable with socket

ADOGF040MSS0005H04

 
Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)


Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Connection

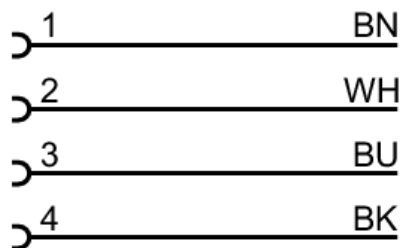

BK =	Core colours :
BN =	black
BU =	brown
WH =	blue
	white