

# E11198





## Connecting cable with socket

ADOGF040MSS0010H04

Article no longer available - archive entry

Alternative articles: EVC152  
When selecting an alternative article and accessories please note that technical data may differ!

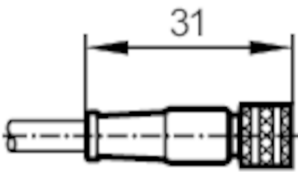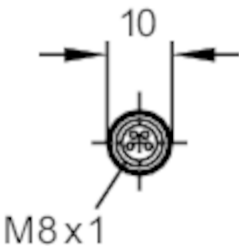

| Application             |      |                                                        |
|-------------------------|------|--------------------------------------------------------|
| Special feature         |      | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone      |      | yes                                                    |
| Electrical data         |      |                                                        |
| Operating voltage       | [V]  | < 60 AC / < 75 DC                                      |
| Protection class        |      | III                                                    |
| Max. current load total | [A]  | 3                                                      |
| Operating conditions    |      |                                                        |
| Ambient temperature     | [°C] | -25...80                                               |
| Protection              |      | IP 68                                                  |
| Mechanical data         |      |                                                        |
| Weight                  | [g]  | 266.8                                                  |
| Dimensions              | [mm] | 10 x 10 x 31                                           |
| Materials               |      | PUR                                                    |
| Moulded-body material   |      | PUR                                                    |
| Material nut            |      | brass, nickel-plated                                   |
| Remarks                 |      |                                                        |
| Pack quantity           |      | 1 pcs.                                                 |

# E11198



## Connecting cable with socket

ADOGF040MSS0010H04

### Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )


### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

Connector: 1 x M8, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



### Connection

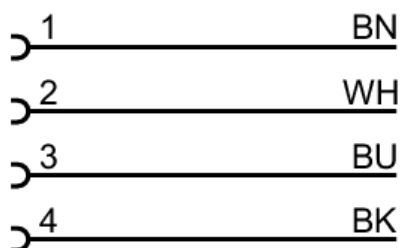

|      |                |
|------|----------------|
| BK = | Core colours : |
| BN = | black          |
| BU = | brown          |
| WH = | blue           |
|      | white          |