

## Connecting cable with socket

ADOAF040VAS0010E04

Article no longer available - archive entry

Alternative articles: EVT140

When selecting an alternative article and accessories please note that technical data may differ!



## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 60 AC / < 75 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 3                 |

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection          |      | IP 68    |

## Mechanical data

|                       |                                 |
|-----------------------|---------------------------------|
| Materials             | PVC                             |
| Moulded-body material | PVC                             |
| Material nut          | stainless steel (1.4404 / 316L) |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E11221



## Connecting cable with socket


ADOAF040VAS0010E04

### Electrical connection


Cable: 10 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Electrical connection - socket

Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm  
Connector: 1 x M8, angled; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Tightening torque: 0.6...0.7 Nm

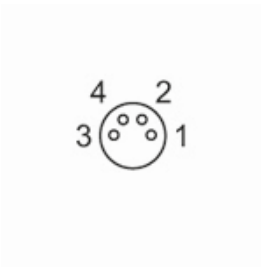

### Connection

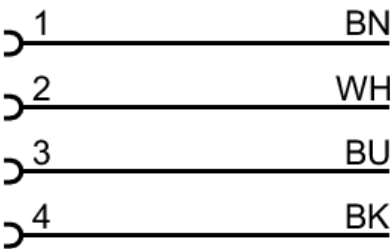

Core colours :  
BK = black  
BN = brown  
BU = blue  
WH = white