


Connecting cable with socket

ADOAO140MSS0005H10

Article no longer available - archive entry

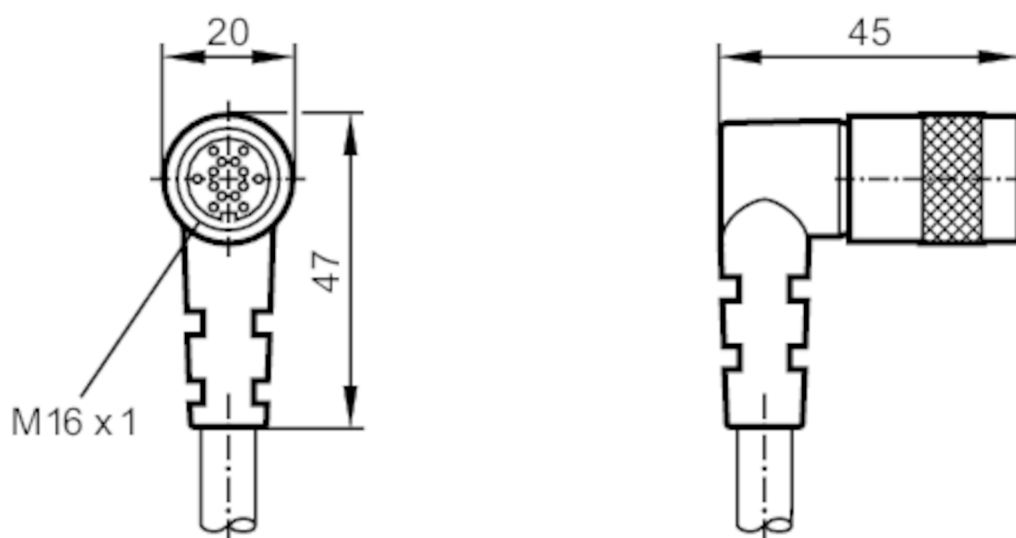

Application		
Special feature	Free from silicone; Halogen-free; Drag chain suitability	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 30 DC
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection	IP 67	
Mechanical data		
Weight	[g]	579
Dimensions	[mm]	45 x 20 x 47
Materials	PUR	
Moulded-body material	PUR	
Material nut	brass, nickel-plated	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 12.5 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	torsional strain	± 180 °/m
Remarks		
Pack quantity	1 pcs.	

E11226



Connecting cable with socket


ADOAO140MSS0005H10

Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 9.2 mm; 8 x 0.34 mm² + 2 x 0.75 mm²

Electrical connection - socket

Connector: 1 x M16, angled; Moulded body: PUR; Locking: brass, nickel-plated

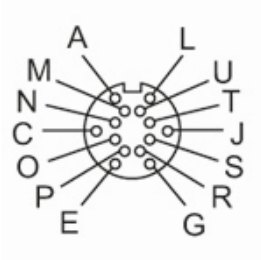

Connection

A	BN
C	WH/GN
E	GY/PK
J	GN
L	BU
N	GN/BN
O	RD/BU
P	WH
S	GY
T	YE

- U:

R:

G:

M:
- not used
- not used
- not used
- not used
- Core colours :
- BN =

BU =

GN =

GY =

PK =

RD =

WH =

YE =
- brown
- blue
- green
- grey
- pink
- red
- white
- yellow