


Connecting cable with socket

ADOAO140MSS0010H10

Article no longer available - archive entry

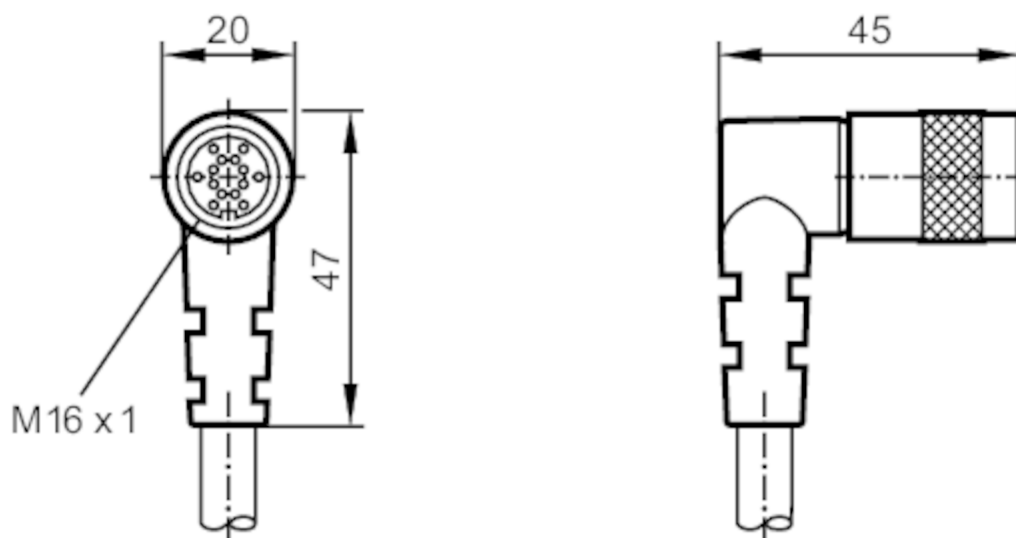

Application		
Special feature	Free from silicone; Halogen-free; Drag chain suitability	
Free from silicone	yes	
Electrical data		
Operating voltage	[V]	< 30 DC
Max. current load total	[A]	3
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection	IP 67	
Mechanical data		
Weight	[g]	1107.5
Dimensions	[mm]	45 x 20 x 47
Materials	PUR	
Moulded-body material	PUR	
Material nut	brass, nickel-plated	
Drag chain suitability	yes	
Drag chain suitability	bending radius for flexible use	min. 12.5 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
	torsional strain	± 180 °/m
Remarks		
Pack quantity	1 pcs.	

E11227



Connecting cable with socket


ADOAO140MSS0010H10

Electrical connection

Cable: 10 m, PUR, Halogen-free, black, Ø 10 mm; 8 x 0.34 mm² + 2 x 0.75 mm²

Electrical connection - socket

Connector: 1 x M16, angled; Moulded body: PUR; Locking: brass, nickel-plated

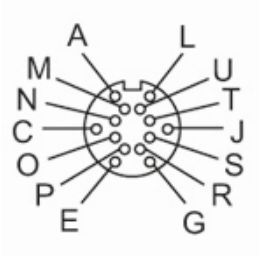

Connection

A	BN
C	WH/GN
E	GY/PK
J	GN
L	BU
N	GN/BN
O	RD/BU
P	WH
S	GY
T	YE

U:	not used
R:	not used
G:	not used
M:	not used
Core colours :	
BN =	brown
BU =	blue
GN =	green
GY =	grey
PK =	pink
RD =	red
WH =	white
YE =	yellow