




Y connection cable

YDOGH080MSS0,15H08STGH040MSS

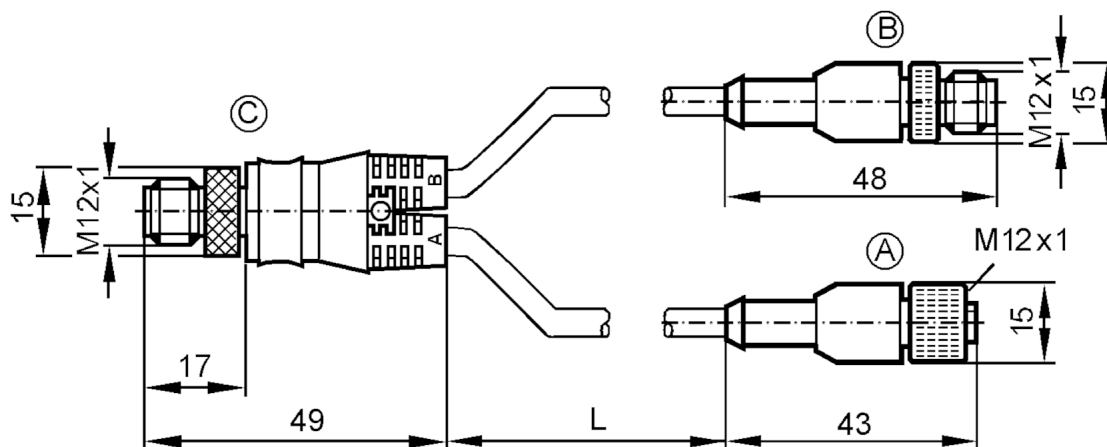

Application

Special feature

Halogen-free

Electrical data

Operating voltage

[V]

< 30 AC / < 36 DC

Operating conditions

Ambient temperature

[°C]

-25...80

Protection

IP 68

Mechanical data

Weight

[g]

63

Materials

PUR

Moulded-body material

PUR

Material nut

brass, nickel-plated


Remarks

Pack quantity

1 pcs.

Electrical connection - socket A


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

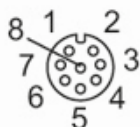

Y connection cable

YDOGH080MSS0,15H08STGH040MSS

Connection

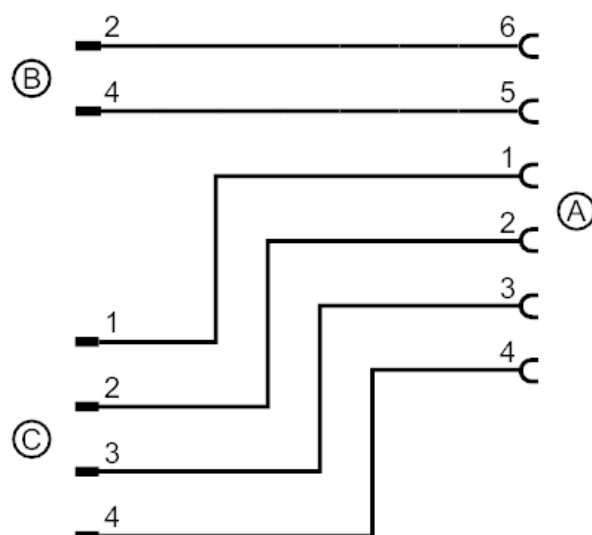

Electrical connection - plug B

Cable: 0.15 m, PUR, Halogen-free, black, Ø 6.2 mm; 2 x 0.25 mm²

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated



Electrical connection - plug C

Cable: 0.15 m, PUR, Halogen-free, black, Ø 6.2 mm; 4 x 0.25 mm²

Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated

