


E11238



Jumper cable with valve plug

AVDAA031--S0020A03

Article no longer available - archive entry

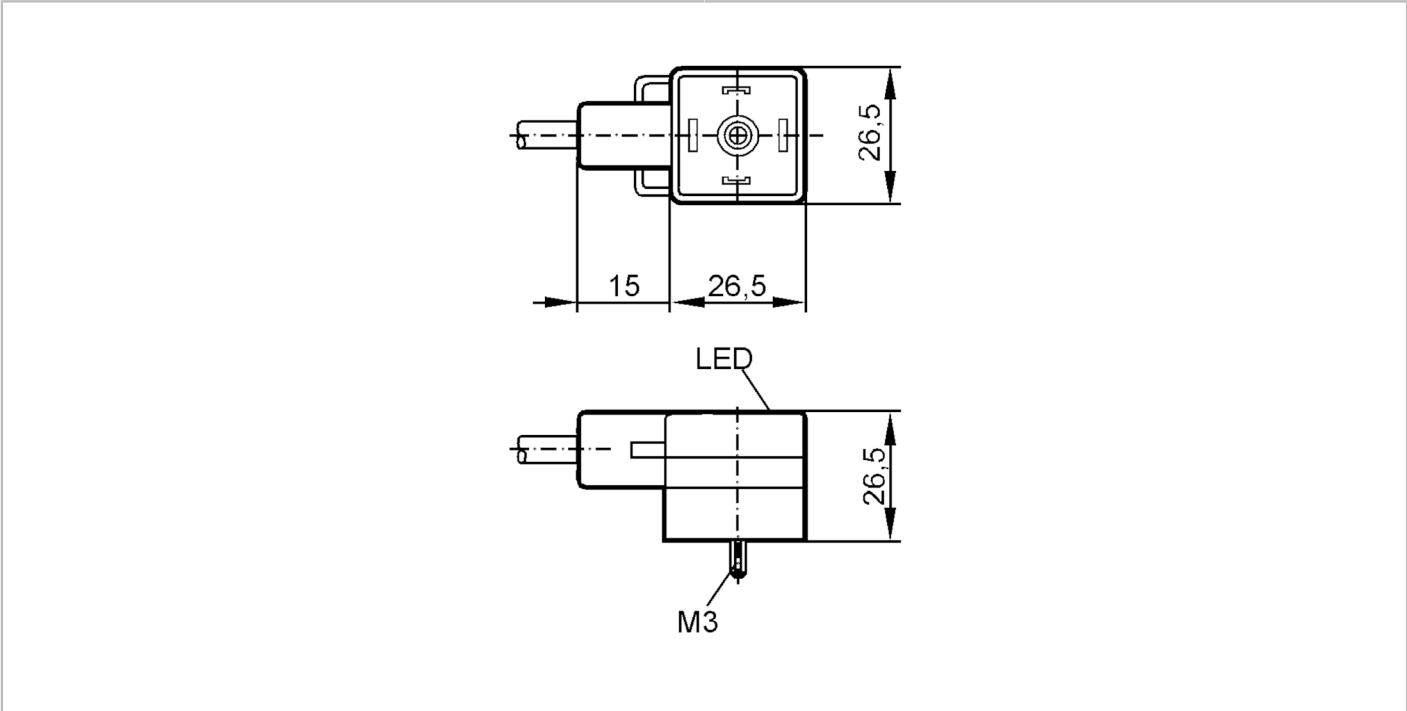

Electrical data		
Operating voltage	[V]	< 24 AC/DC
Overvoltage protection		yes; (VDR)
Operating conditions		
Ambient temperature	[°C]	-25...70
Protection		IP 67
Mechanical data		
Materials		PUR
Moulded-body material		PUR
Displays / operating elements		
Display	switching status	1 x LED, yellow
Аксессуары		
Items supplied		screw panel for labelling
Remarks		
Pack quantity		1 pcs.

E11238



Jumper cable with valve plug

AVDAA031--S0020A03

Electrical connection

Cable: 20 m, PVC, black, Ø 5 mm; 3 x 0.5 mm² (16 x Ø 0.2 mm)

Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: PUR



Connection



BN =
BU =
GN/YE =

Core colours :
brown
blue
green/yellow