


E11274



Connection cable

VDOAR040PLS0002HSTGH040VAS

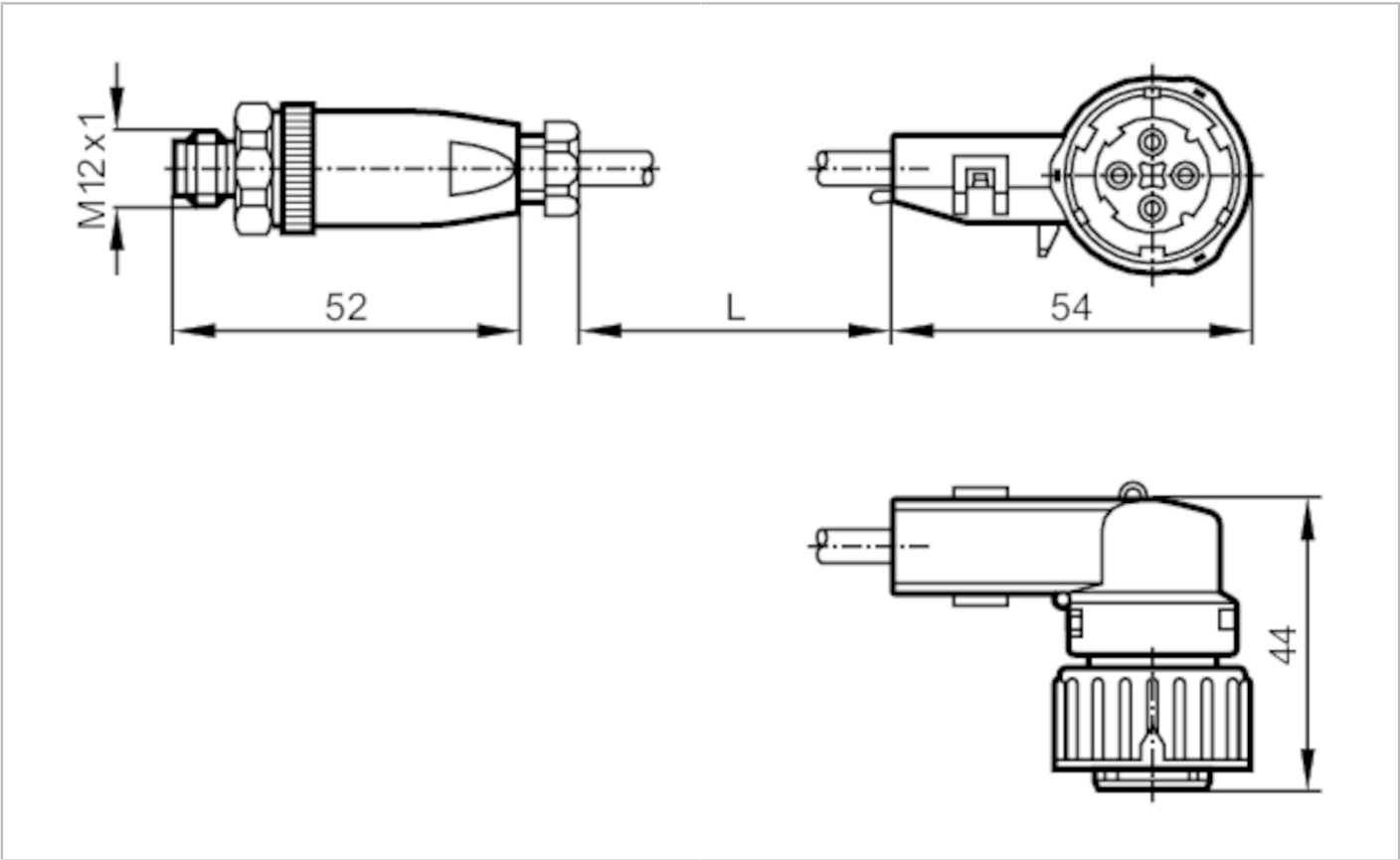

Application	
Special feature	Halogen-free
Design	for communication with the programming unit PP2000
Electrical data	
Operating voltage	[V] 9.6...30 DC
Operating conditions	
Ambient temperature	[°C] -40...85
Protection	IP 67; (Connecting cable with socket: IP 67 / IP 69K)
Mechanical data	
Weight	[g] 131
Moulded-body material	PA / Hytrel G-4774
Remarks	
Pack quantity	1 pcs.

E11274



Connection cable

VDOAR040PLS0002HSTGH040VAS

Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 6 mm; 4 x 0.5 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PA



Connection

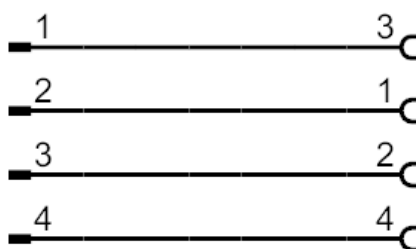

Electrical connection - socket

Connector: 1 x bayonet, angled; Moulded body: Hytrel G-4774

