

E11282




Connecting cable with plug

ASTGH040MSS0003H04

Article no longer available - archive entry

Alternative articles: EVC077
When selecting an alternative article and accessories please note that technical data may differ!

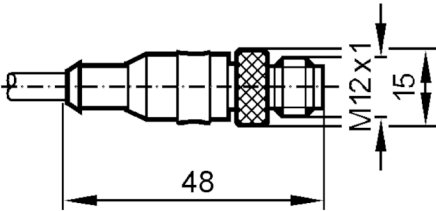

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Dimensions [mm]	15 x 15 x 48
Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

E11282



Connecting cable with plug


ASTGH040MSS0003H04

Electrical connection

Cable: 3 m, PUR, Halogen-free, black, Ø 4.5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

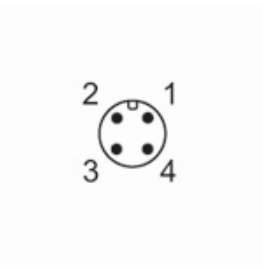

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white