


E11293



Adapter plug

ESTGH040MSS0,05E04 (M20)

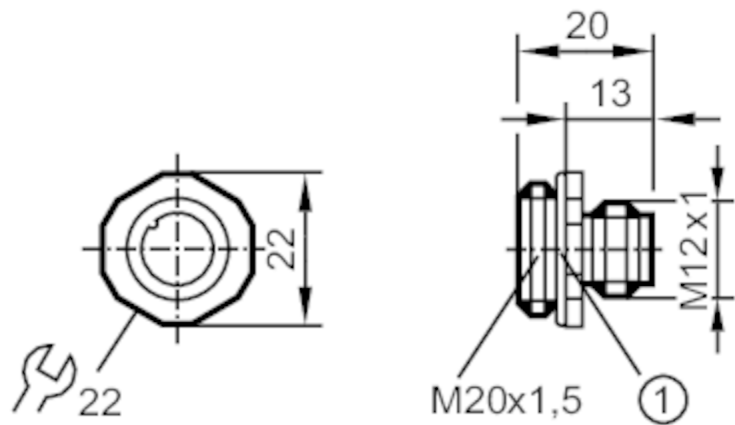

Electrical data		
Operating voltage	[M]	< 250 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	22.6
Mounting thread		M20
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 0.05 m, PVC; 4 x 0.25 mm²	

Electrical connection - plug	
Connector: 1 x M12, straight; coding: A; Moulded body: brass, nickel-plated	



E11293



Adapter plug

ESTGH040MSS0,05E04 (M20)

Connection

1	BN
2	WH
3	BU
4	BK

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white