


Connecting cable with plug

ASTGH030VAS0001A03

Article no longer available - archive entry

Alternative articles: EVC076

When selecting an alternative article and accessories please note that technical data may differ!

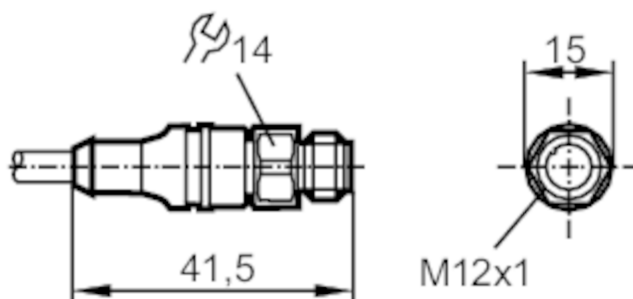

Application

Special feature	Free from silicone
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
-------------------	-----	---------------------

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Dimensions	[mm]	15 x 15 x 41.5
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (1.4404 / 316L)

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E11296



Connecting cable with plug


ASTGH030VAS0001A03

Electrical connection

Cable: 1 m, PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L)

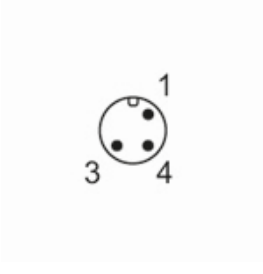

Connection

1	BN
3	BU
4	BK

BK = Core colours :
BN = black
BU = brown
BK = blue