

# E11318




## Connection cable

VDOGF030MSS0005B03STGF030MSS

Article no longer available - archive entry

Alternative articles: E11353

When selecting an alternative article and accessories please note that technical data may differ!

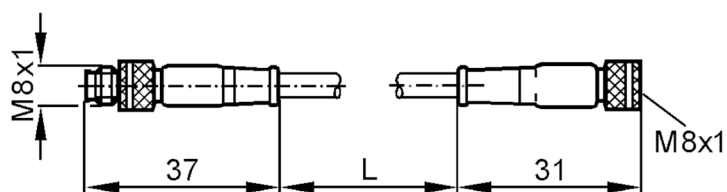

### Electrical data

Operating voltage [V] 10...30 DC

Protection class III

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 68

### Mechanical data

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection - plug

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.6...0.7 Nm



# E11318



## Connection cable

VDOGF030MSS0005B03STGF030MSS

### Electrical connection

Cable: 5 m, TPU, black, Ø 4.5 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection



### Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.6...0.7 Nm

