


Ethernet connection cable

VSTGN040ZDS00,5L04STGN040ZDS

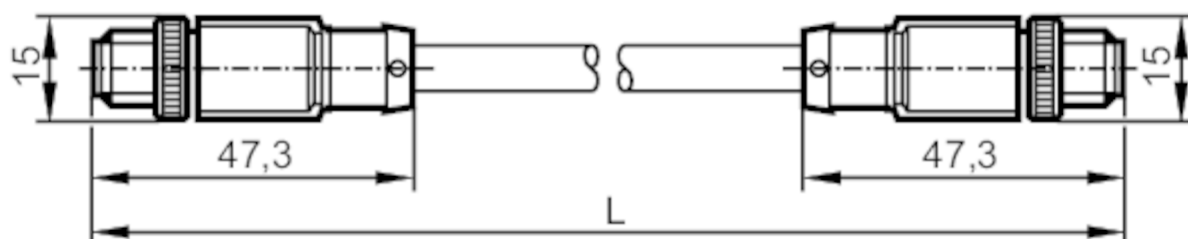

Application

Special feature

Gold-plated contacts; Screened cable

Design

Ethernet cable, D-coded

Electrical data

Operating voltage

[V]

< 50 AC / < 60 DC

Protection class

III

Max. current load total

[A]

4

Operating conditions

Ambient temperature

[°C]

-20...90

Protection

IP 67

Mechanical data

Weight

[g]

66.1

Dimensions

[mm]

15 x 15 x 47.3

Materials

TPU

Moulded-body material

TPU

Material nut

diecast zinc, nickel-plated

Remarks

Pack quantity

1 pcs.

E12422



Ethernet connection cable

VSTGN040ZDS00,5L04STGN040ZDS

Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected



Electrical connection

Cable: 0.5 m, PVC, green, shielded; 4 x 0.34 mm²

Connection



Electrical connection - plug

Connector: 1 x M12, straight; coding: D; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

