


E12425

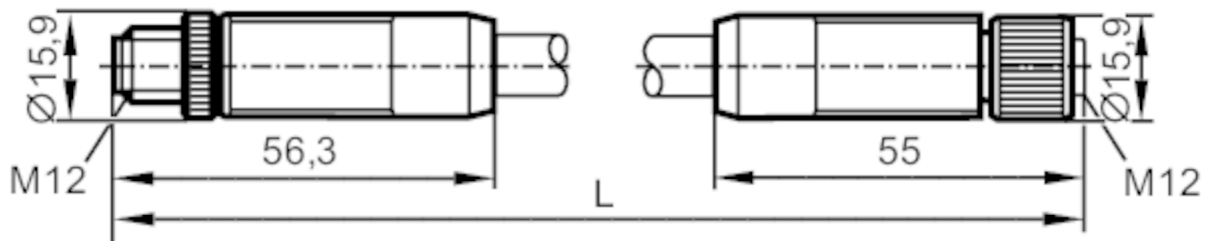

Connection cable

VDOGD040ZDS00,5H04STGD040ZDS



Application

Special feature	Gold-plated contacts; Drag chain suitability
Design	power cable, T-coded

Electrical data

Operating voltage	[V]	< 60 DC
Max. current load total	[A]	12

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 67

Mechanical data

Weight	[g]	105.4
Dimensions	[mm]	15.4 x 15.4 x 54.8
Materials		PUR
Moulded-body material		PUR
Material nut		diecast zinc, nickel-plated
Drag chain suitability		yes
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	bending radius for fixed installation	min. 5 x cable diameter
	travel speed	max. 3 m/s at 5 m horizontal travel length and max. acceleration of 5 m/s ²
	bending cycles	> 4 Mio.

Remarks

Pack quantity	1 pcs.
---------------	--------

E12425



Connection cable

VDOGD040ZDS00,5H04STGD040ZDS

Electrical connection - plug


Connector: 1 x M12, straight; coding: T; Moulded body: PUR; Locking: diecast zinc, nickel-plated; Contacts: gold-plated



Electrical connection

Cable: 0.5 m, PUR, black; 4 x 1.5 mm²

Connection

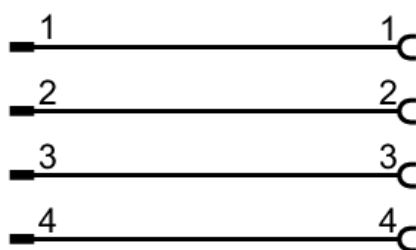

Electrical connection - socket

Connector: 1 x M12, straight; coding: T; Moulded body: PUR

