


E12437

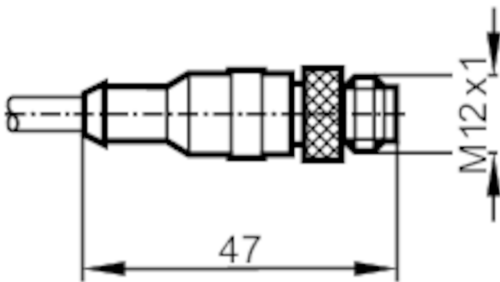

Connecting cable with plug


ASTGH080MSS0005H08



Electrical data		
Operating voltage	[V]	< 30 AC / < 36 DC
Operating conditions		
Ambient temperature	[°C]	-25...80
Protection		IP 67
Mechanical data		
Weight	[g]	313.7
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

Electrical connection	
Cable: 5 m, PUR, black, Ø 6.8 mm; 8 x 0.25 mm²	

Electrical connection - plug	
Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Tightening torque: 0.7...0.9 Nm	

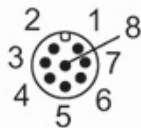

E12437



Connecting cable with plug

ASTGH080MSS0005H08

Connection

<u>1</u>	<u>BN</u>
<u>2</u>	<u>WH</u>
<u>3</u>	<u>BU</u>
<u>4</u>	<u>BK</u>
<u>5</u>	<u>GY</u>
<u>6</u>	<u>PK</u>
<u>7</u>	<u>VT</u>
<u>8</u>	<u>OG</u>

colours to DIN EN 60947-5-2

Core colours :

BK =	black
BN =	brown
BU =	blue
GY =	grey
PK =	pink
OG =	orange
VT =	lilac
WH =	white