


Connection cable

ADOGH050MSS00,3K05STGK120MSS

Article no longer available - archive entry

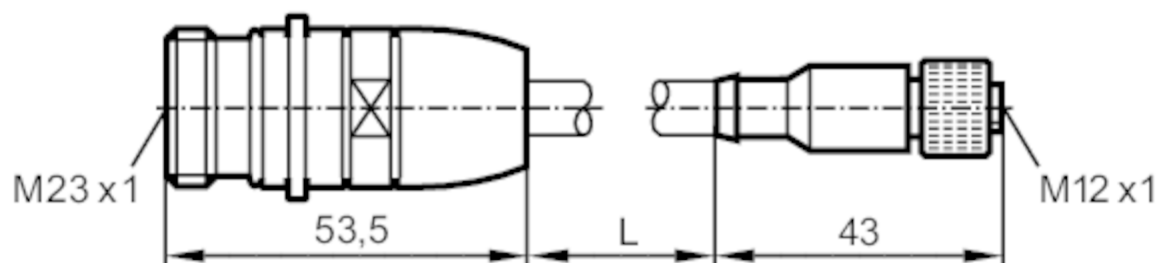

Application

Special feature

Gold-plated contacts; Screened cable

Electrical data

Operating voltage

[V]

< 30 AC / < 36 DC

Operating conditions

Ambient temperature

[°C]

-20...90

Protection

IP 67

Mechanical data

Weight

[g]

110.1

Moulded-body material

brass, nickel-plated / TPU

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

E12459




Connection cable

ADOGH050MSS00,3K05STGK120MSS

Electrical connection - plug


Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

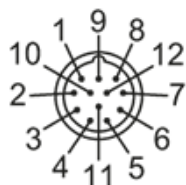

Electrical connection

Cable: 0.3 m, PUR, black, Ø 4.8 mm, shielded; 5 x 0.25 mm²

Connection

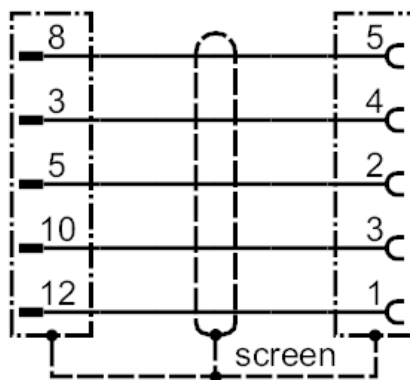

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, black; Locking: brass, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

