


E12460




Connection cable

ADOGH080MSS00,3K05STGK120MSS

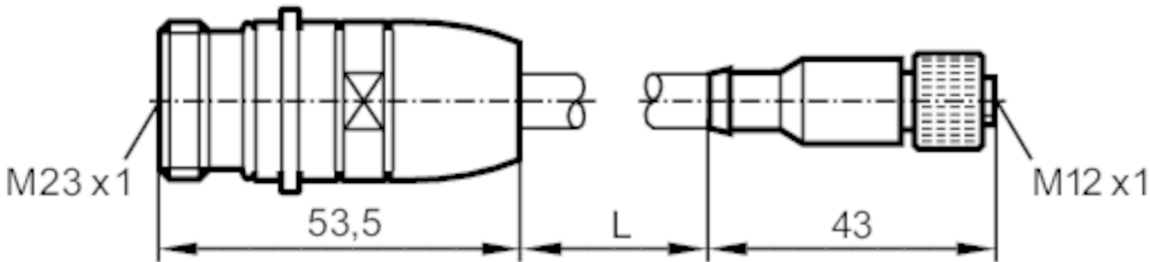

Application	
Special feature	Gold-plated contacts; Screened cable
Electrical data	
Operating voltage	[V] < 30 AC / < 36 DC
Operating conditions	
Ambient temperature	[°C] -20...90
Protection	IP 67
Mechanical data	
Weight	[g] 111.4
Moulded-body material	brass, nickel-plated / TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.

Electrical connection - plug	
Connector: 1 x M23, straight; Moulded body: brass, nickel-plated; Locking: brass, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected	

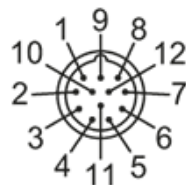

E12460




Connection cable

ADOGH080MSS00,3K05STGK120MSS

Electrical connection

Cable: 0.3 m, PUR, black, Ø 6 mm, shielded; 8 x 0.25 mm²

Connection

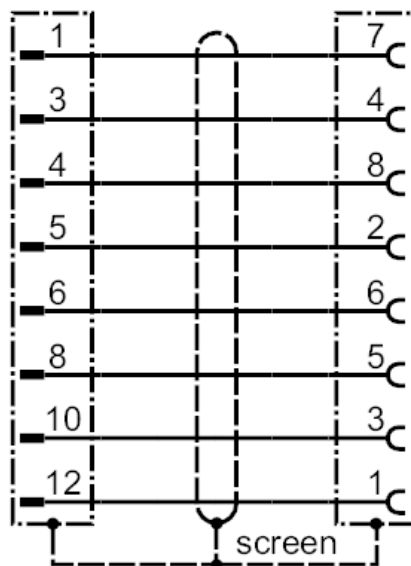

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPU, black; Locking: brass, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

