


Y-splitter

ZDO2H040MSS0000-00STGH040MSS

Article no longer available - archive entry

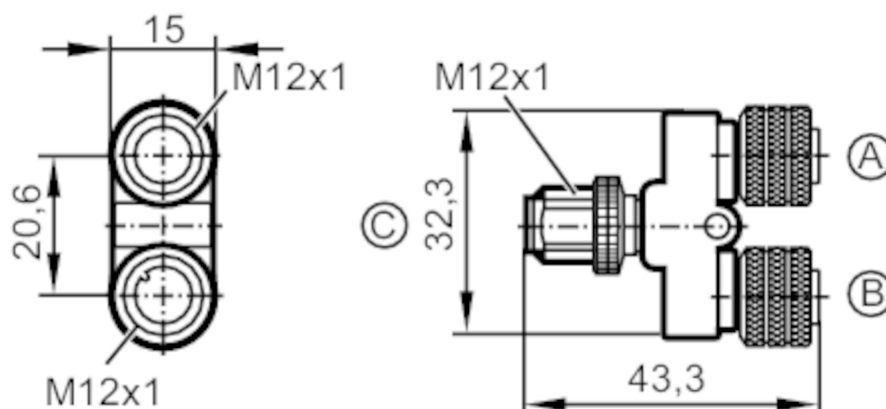

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 60 AC/DC
Max. current load per module/slot	[A]	12
Max. current load total	[A]	12; (...40 °C)

Operating conditions

Ambient temperature	[°C]	-25...70
Protection		IP 67

Mechanical data

Weight	[g]	24.6
Materials		TPU
Moulded-body material		TPU
Material nut		diecast zinc
Connector type		M12

Remarks


Pack quantity	1 pcs.
---------------	--------

Y-splitter

ZDO2H040MSS0000-00STGH040MSS

Electrical connection

Connection

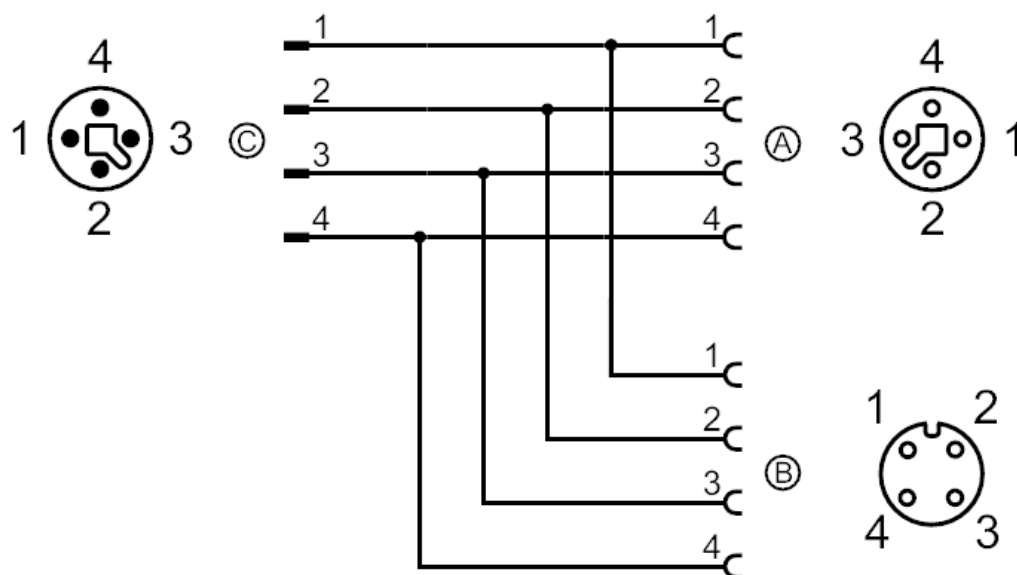

Electrical connection - plug

Connector: 1 x M12; Moulded body: TPU; Locking: diecast zinc; Contacts: gold-plated

Electrical connection - socket

Connector: 2 x M12; Moulded body: TPU; Locking: diecast zinc; Contacts: gold-plated