


Y-splitter

ZDO2H050ZDS0000-00STGH050ZDS

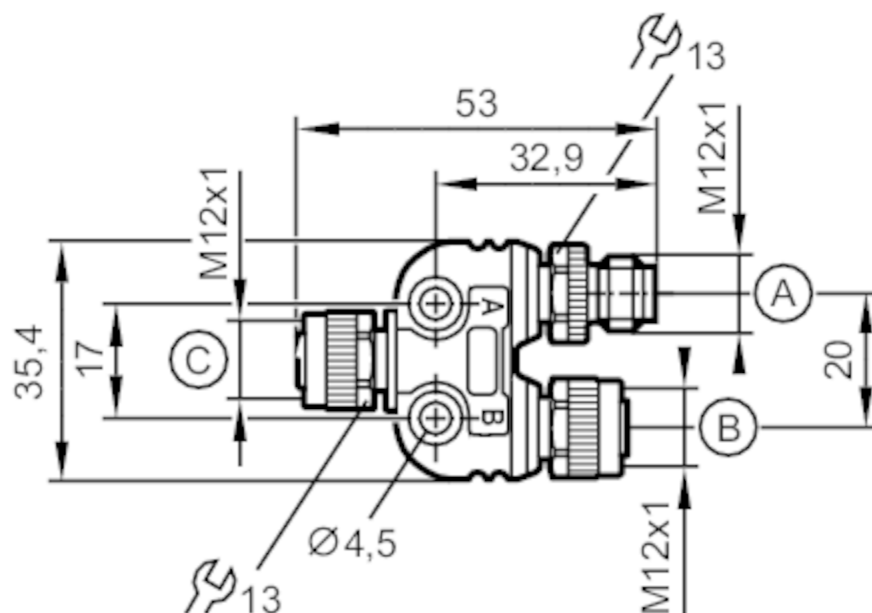

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	60 AC/DC
Protection class		II
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	37.1
Materials		PUR black
Moulded-body material		PUR, Halogen-free

Remarks

Pack quantity	1 pcs.
---------------	--------

Y-splitter

ZDO2H050ZDS0000-00STGH050ZDS


Electrical connection - plug

Connector: 1 x M12; coding: A; Moulded body: PUR, Halogen-free; Contacts: gold-plated



Electrical connection - socket

Connector: 2 x M12; coding: A; Moulded body: PUR, Halogen-free; Contacts: gold-plated

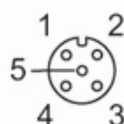

Connection

