


Connection cable

VDOGH040MSS0007H04STGH04MSS

customer-specific

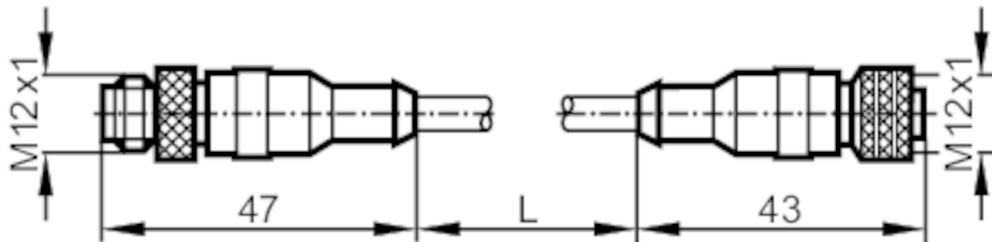

Application

Special feature	Drag chain suitability
Application	microbe-resistant
Oil resistant	yes
UV resistant	yes

Electrical data

Operating voltage	[V]	< 250 AC / < 300 DC
Protection class		II
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-40...90
Ambient temperature (moving)	[°C]	-15...70
Protection		IP 65; IP 67

Mechanical data

Weight	[g]	309.5
Materials		housing: TPE-U black; Sealing: FKM
Material nut		diecast zinc, nickel-plated
Drag chain suitability		yes
Drag chain suitability	bending radius for flexible use	min. 8 x cable diameter
	bending radius for fixed installation	min. 4 x cable diameter

Remarks

Remarks	resistant to high mechanical stress
Notes	customer-specific

E12535



Connection cable

VDOGH040MSS0007H04STGH04MSS

Pack quantity

1 pcs.

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 7 m, PUR, black, Ø 5.8 mm; twisted pairs; 2 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

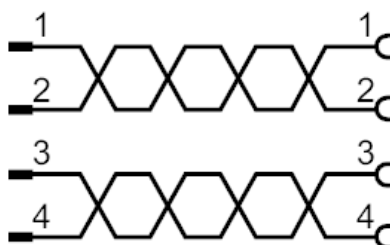

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm

