


E12538



Damping magnet

MAGNET M6.1 NEODYM, DRILL HOLE

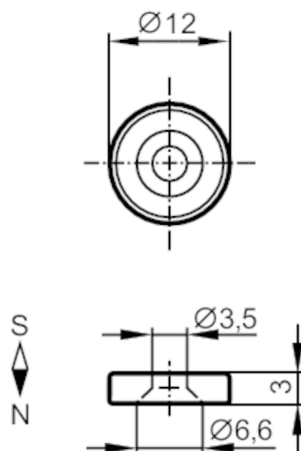

Operating conditions

Ambient temperature	[°C]	-40...80
---------------------	------	----------

Mechanical data

Weight	[g]	3
Dimensions	[mm]	Ø 12 / L = 3
Materials		neodymium
Magnetic field strength	[mT]	250

Remarks

Pack quantity	1 pcs.
---------------	--------