


# E12553



## Y connection cable

YDOGS040PLS0002H02

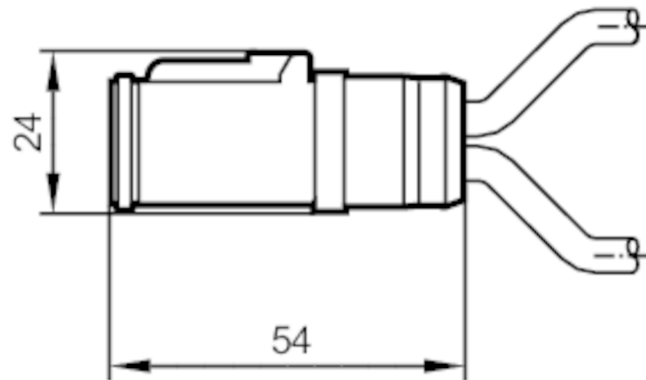

### Application

|                    |                                                          |
|--------------------|----------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Drag chain suitability |
| Free from silicone | yes                                                      |

### Electrical data

|                         |     |           |
|-------------------------|-----|-----------|
| Operating voltage       | [V] | 8...32 DC |
| Protection class        |     | III       |
| Max. current load total | [A] | 4         |

### Operating conditions

|                              |      |                                      |
|------------------------------|------|--------------------------------------|
| Ambient temperature          | [°C] | -40...85                             |
| Ambient temperature (moving) | [°C] | -20...85                             |
| Protection                   |      | IP 67; (mating connector plugged in) |

### Mechanical data

|                              |                                 |                                                                                    |
|------------------------------|---------------------------------|------------------------------------------------------------------------------------|
| Weight                       | [g]                             | 154.2                                                                              |
| Dimensions                   | [mm]                            | 24 x 24 x 54                                                                       |
| Materials                    |                                 | PA                                                                                 |
| Number of ports splitter box |                                 | 2                                                                                  |
| Drag chain suitability       |                                 | yes                                                                                |
| Drag chain suitability       | bending radius for flexible use | min. 10 x cable diameter                                                           |
|                              | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s² |
|                              | bending cycles                  | > 5 Mio.                                                                           |
|                              | torsional strain                | ± 180 °/m                                                                          |

# E12553



## Y connection cable

YDOGS040PLS0002H02

### Remarks


|               |        |
|---------------|--------|
| Pack quantity | 2 pcs. |
|---------------|--------|

### Electrical connection


Cable: 2 m, PUR, Halogen-free, black, Ø 5.4 mm; 2 x 0.50 mm<sup>2</sup> (28 x Ø 0.15 mm )

### Electrical connection - socket

Connector: 1 x DEUTSCH connector, straight; Contacts: nickel-plated

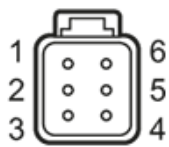

### Connection

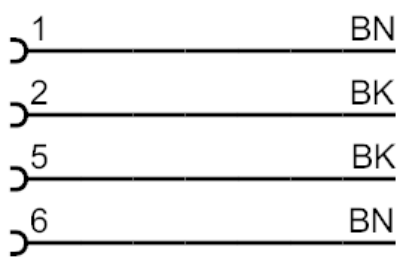

|      |                |
|------|----------------|
| BK = | Core colours : |
| BN = | black          |
|      | brown          |