


E12557



Connection cable

VDOGS040PLS0002H04DOGS040PLS

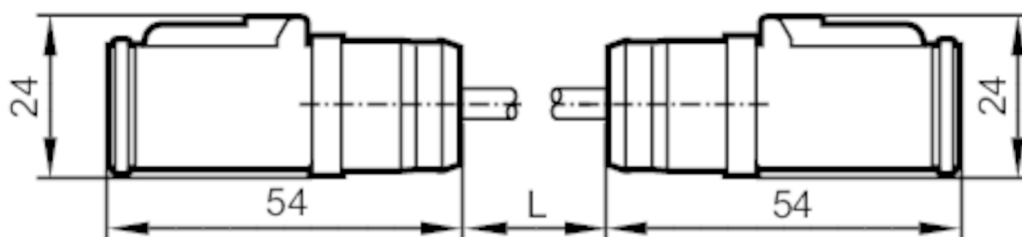

Application		
Special feature		Free from silicone; Halogen-free
Free from silicone		yes
Electrical data		
Operating voltage	[V]	12...24 DC
Protection class		III
Max. current load total	[A]	4
Operating conditions		
Ambient temperature	[°C]	-40...85
Ambient temperature (moving)	[°C]	-30...70
Protection		IP 67; (mating connector plugged in)
Mechanical data		
Weight	[g]	173.7
Moulded-body material		PA
Remarks		
Pack quantity		1 pcs.

E12557



Connection cable

VDOGS040PLS0002H04DOGS040PLS

Electrical connection

Cable: 2 m, PUR, Halogen-free, lilac, Ø 6.4 mm; twisted; 2 x 0.50 mm² (28 x 0.15 mm) + 2 x 1 mm² (52 x 0.15 mm)

Electrical connection - socket

Connector: 2 x DEUTSCH connector, straight; Moulded body: PA; Contacts: nickel-plated



Connection

