


E12565



Connecting cable with AMP connector

ADOGX060--A002E06

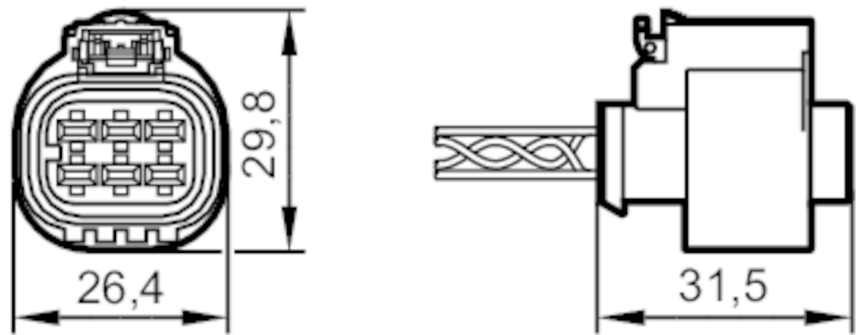

Electrical data		
Operating voltage	[V]	12...24 DC
Operating conditions		
Ambient temperature	[°C]	-40...100
Ambient temperature (moving)	[°C]	-40...100
Protection		IP 67; (mating connector plugged in)
Mechanical data		
Weight	[g]	246.4
Materials		PBT
Remarks		
Pack quantity		1 pcs.

E12565



Connecting cable with AMP connector


ADOGX060--A002E06

Electrical connection

Cable: 2 m, PVC; 4 x 2.5 mm² + 2 x 0.5 mm²

Electrical connection - socket

Connection

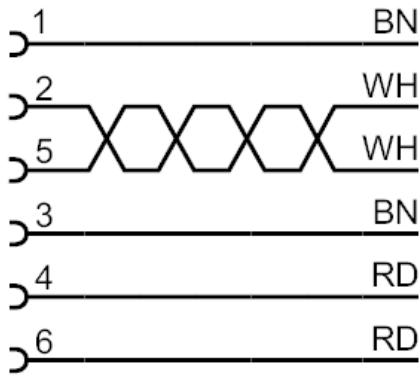

BN = Core colours :
RD = brown
WH = red
white

Connector: 1 x AMP connector, straight; Contacts: nickel-plated